


Заглушка EuropacPRO для винтового крепления к боковой панели повышенной прочности, ширина 84 НР, 295 мм, глубина печатной платы 180 мм

CATALOG NUMBER

24568-016

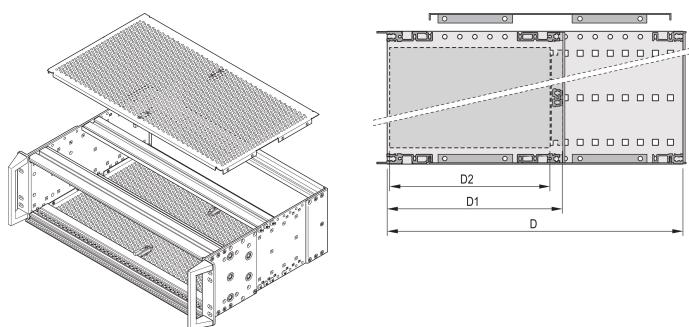

Защитная крышка используется для электромагнитного экранирования или в качестве механической защиты.

CERTIFICATIONS



FEATURES

Степень перфорации 58 %

PRODUCT ATTRIBUTES

Глубина мм: 295mm

Package Quantity: 2

Finish: Passivated

Material: Алюминий

Product Family: EuropacPRO

Product Type: Cover Plate

Rack Width: 84HP

Type: С перфорацией

Works With: Блочный каркас

Package Unit: Pair

Torque: 2.1N·m

ADDITIONAL PRODUCT DETAILS

Дополнительно предоставляется механизм блокировки верхней крышки, который также фиксирует верхнюю крышку на передней и задней направляющих.

4 контактных ЭМС-пружины из нержавеющей стали на каждый блочный каркас необходимы для экранирования, заказываются отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE