


# Направляющая стандартного типа, поликарбонат, 340 мм, ширина канавки 2 мм, цвет: красный/серебристый, 10 шт.

## CATALOG NUMBER

**24568-380**

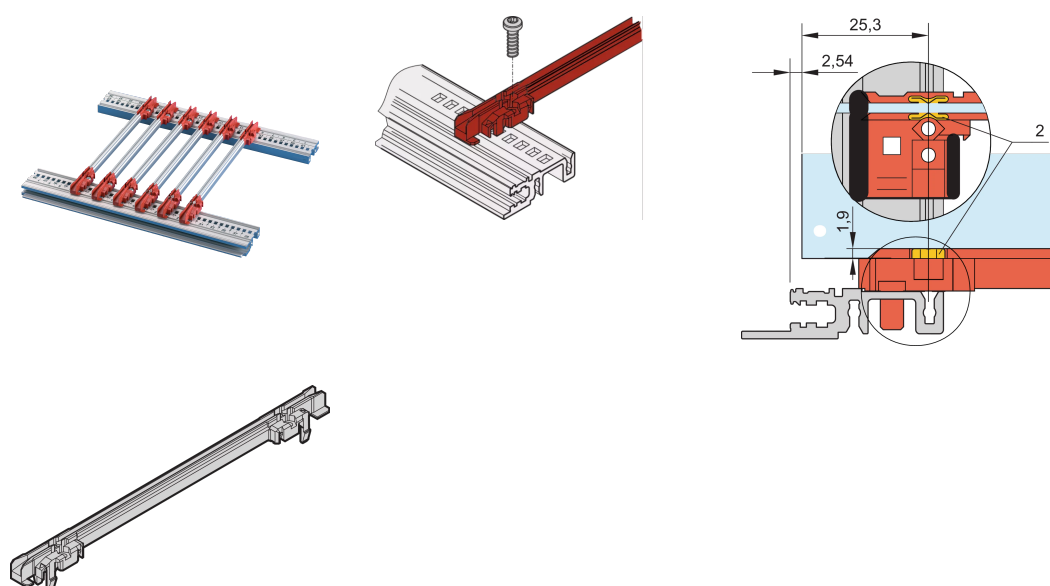

New generation of accessory type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies.

## CERTIFICATIONS



## FEATURES

Пластиковые направляющие стандартного типа нового поколения для надежной фиксации печатных плат или вставных блоков

Значительно повышенная устойчивость, благодаря оптимизированной конструкции и высококачественному материалу (поликарбонат)

«Не содержат галогенов», согласно IEC 61249-2-21

Могут быть закреплены на горизонтальных рельсах (алюминиевый экструдированный профиль) или на панелях толщиной 1,5 мм

Для более высоких требований в отношении ударных нагрузок и вибрации направляющие могут прикручиваться болтами к горизонтальной рейке (тип H и тип R)

Доступен дополнительный зажим ESD для проводящего контакта между печатной платой и горизонтальным рельсом

Температура хранения: от -40 °C до 130 °C

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

## PRODUCT ATTRIBUTES

Color: Красный

Package Quantity: 10

Board Depth: 340mm

Groove Width: 2

Complies With: EN 45545-2

Material: Fiber-Reinforced Plastic

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac

Product Type: Направляющие рельсы

Type: Standard

Works With: Блочный каркас; Coffrets; 19" Chassis; Системы

## ADDITIONAL PRODUCT DETAILS

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**