


Монтажный комплект для откидной ручки RatiорасPro, высота 3 U, ширина стойки 42 HP, 315 мм

CATALOG NUMBER

24571-353

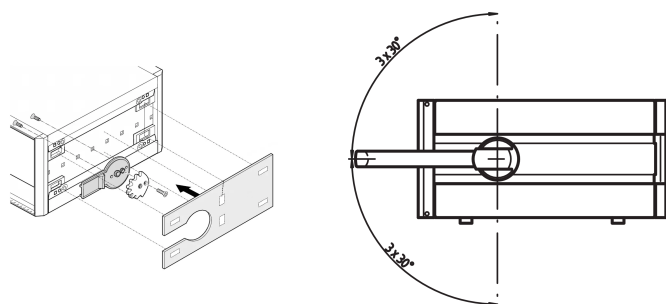

Данный монтажный комплект должен использоваться в случае, если необходимо установить откидную ручку. Стандартные боковые крышки следует заменить.

CERTIFICATIONS



FEATURES

Алюминиевая боковая панель с порошковым покрытием RAL 9006, адаптер и монтажный материал.

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 42HP

Глубина мм: 315mm

Package Quantity: 2

Finish: Powder Coated

Material: Алюминий

Product Family: RatiopacPRO; RatiopacPRO AIR

Product Type: Монтажные детали

Type: Tip-Up Handle Kit

Works With: Coffrets

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE