


Система CompactPCI с источником питания АТХ, высота 3 U, 8 слотов

CATALOG NUMBER

24579-031

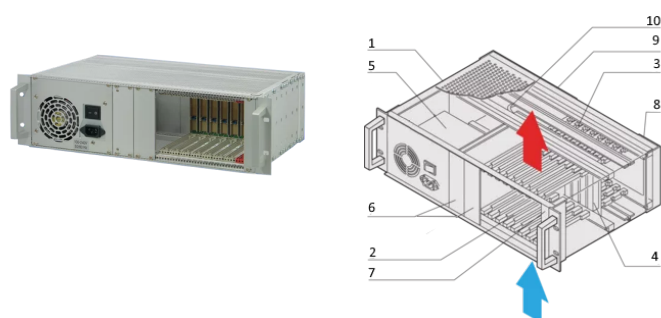

Безвентиляторная система CompactPCI 3 U с вертикальным каркасом для печатных плат на восемь плат 3 U и восемь плат RTM. Встроенный источник питания АТХ.

CERTIFICATIONS



FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, глубина 160 мм; Задняя панель ввода-вывода: 3 U, глубина 80 мм

Объединительная плата с 8 слотами, 3 U, 32 -разрядная; системный слот справа; Допускается использование ЦП шириной 8 HP

Отвод тепла путем конвекции, воздушный поток снизу вверх

Блок питания АТХ, 300 Вт

Возможность установки DVD-дисков Slim-Line и жесткого диска

PRODUCT ATTRIBUTES

Product Type: System
Number of Slots: 8
Type: 19" Rack Mount
Backplane Type: 3 U CompactPCI
Data Transfer: 32-bit PCI Bus
Power per Slot: 10W
Input Voltage AC: 100 – 240V
Rack Height: 3U
Power Supply Type: (1) ATX PSU
Power Supply Included: Да
Rear I/O: Да
Complies With: PICMG 2.0 R3.0
Глубина мм: 275mm
Высота мм: 132.55mm
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	+971.4.378.1700
Chat with us:	Betschdorf, France	Qingdao, China	Bangalore, India
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	+91.80.6715.2001
	Warsaw, Poland	Singapore	Istanbul, Turkey
	+48.22.209.98.35	+65.6768.5800	+90.216.250.7374
	Assago, Italy	Shin-Yokohama, Japan	Chat with us:
	+39.02.932.7141	+81.45.476.0271	nvent.com/schroff
	Chat with us:	Chat with us:	
	nvent.com/schroff	nvent.com/schroff	



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE