


Система CPPI для подключаемого источника питания АТХ, горизонтальная, высота 3 U, 6 слотов

CATALOG NUMBER

24579-080

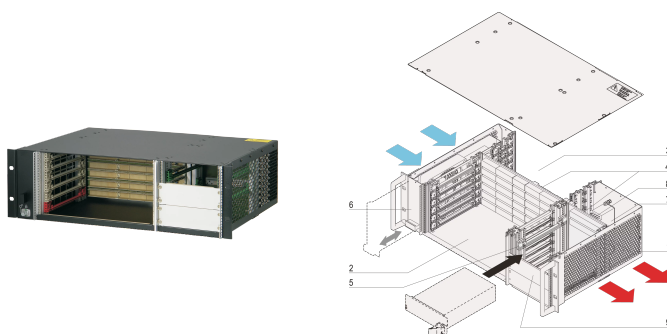

Система 3 U CompactPCI с горизонтальным каркасом для печатных плат на шесть плат 6 U, шесть плат RTM и один сменный источник питания CompactPCI 3 U. Возможность установки до трех сменных источников питания.

CERTIFICATIONS



FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с горизонтальным каркасом для печатных плат. Фронтальная плата: 6 U, глубина 160 мм; Задняя панель ввода-вывода: 6 U, глубина 80 мм

Объединительная плата (объединительная плата для сигналов и питания как одно целое) 6 слотов, 6 U, 64-битная, системный слот слева, разъем питания (2x P47)

Отвод тепла с помощью вентилятора с горячей заменой (воздушный поток слева направо)

Подготовлена для установки 19-дюймового источника питания CompactPCI (3 U, 8 HP)

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 6

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 3U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Нет

Rear I/O: Да

Complies With: PICMG 2.0 R3.0

Глубина мм: 275mm

Высота мм: 132.5mm

Ширина мм: 449mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

Вариант исполнения на 48 В пост. тока по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE