


Система CPPI с подключаемым источником питания, высота 4 U, 8 слотов

CATALOG NUMBER

24579-260

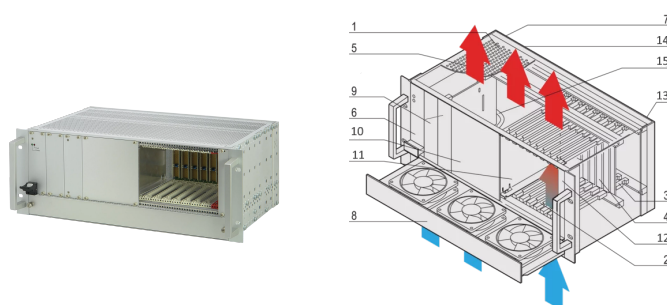

Система 4 U CompactPCI Serial с вертикальным каркасом для печатных плат на восемь плат 3 U, восемь плат RTM и одним подключаемым источником питания 3U.

CERTIFICATIONS



FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, глубина 160 мм; Задняя панель ввода-вывода: 3 U, глубина 80 мм

Объединительная плата с 8 слотами, 3 U, 32 -разрядная; системный слот справа; Допускается использование ЦП шириной 8 НР; Силовая объединительная плата

Отвод тепла при помощи вентилятора 1 U с горячей заменой, воздушный поток снизу вверх

19-дюймовый блок питания, 250 Вт, 3 U, 8 НР

Возможность установки жесткого диска

PRODUCT ATTRIBUTES

Product Type: System
Number of Slots: 8
Type: 19" Rack Mount
Backplane Type: 3 U CompactPCI
Data Transfer: 32-bit PCI Bus
Power per Slot: 40W
Input Voltage AC: 100 – 240V
Airflow Direction: Bottom to Top
Rack Height: 4U
Power Supply Type: (1) Pluggable PSU
Power Supply Included: Да
Rear I/O: Да
Complies With: PICMG 2.0 R3.0
Глубина мм: 275mm
Высота мм: 177mm
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE