


# Система CompactPCI с источником питания АТХ. Настольный корпус, высота 4 U, 8 слотов, ширина стойки 84 HP

## CATALOG NUMBER

**24579-602**

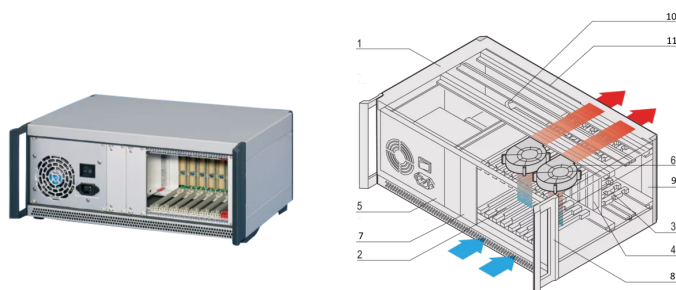

Настольное шасси CompactPCI с вертикальным каркасом для печатных плат на восемь плат 3 U, восемь плат RTM 3 U и одним встроенным источником питания АТХ.

## CERTIFICATIONS



## FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, глубина 160 мм; Задняя панель ввода-вывода: 3 U, глубина 80 мм

Объединительная плата с 8 слотами, 3 U, 32-битная, системный слот справа; Допускается использование ЦП шириной 8 HP

Отвод тепла осуществляется двумя радиальными вентиляторами, воздушный поток спереди назад

Блок питания АТХ, 300 Вт

Возможность установки DVD-дисков Slim-Line и жесткого диска

PRODUCT ATTRIBUTES

|                                  |
|----------------------------------|
| Product Type: System             |
| Number of Slots: 8               |
| Type: Настольный корпус          |
| Backplane Type: 3 U CompactPCI   |
| Data Transfer: 32-bit PCI Bus    |
| Power per Slot: 40W              |
| Input Voltage AC: 100 – 240V     |
| Airflow Direction: Front to Rear |
| Rack Height: 4U                  |
| Power Supply Type: (1) ATX PSU   |
| Power Supply Included: Да        |
| Rear I/O: Да                     |
| Complies With: PICMG 2.0 R3.0    |
| Глубина мм: 275mm                |
| Высота мм: 177mm                 |
| Package Quantity: 1              |

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE