


Varistar CP Top Cover Fan, Energy Efficient, Height 38 mm, 171 m³/h

CATALOG NUMBER

24630-117

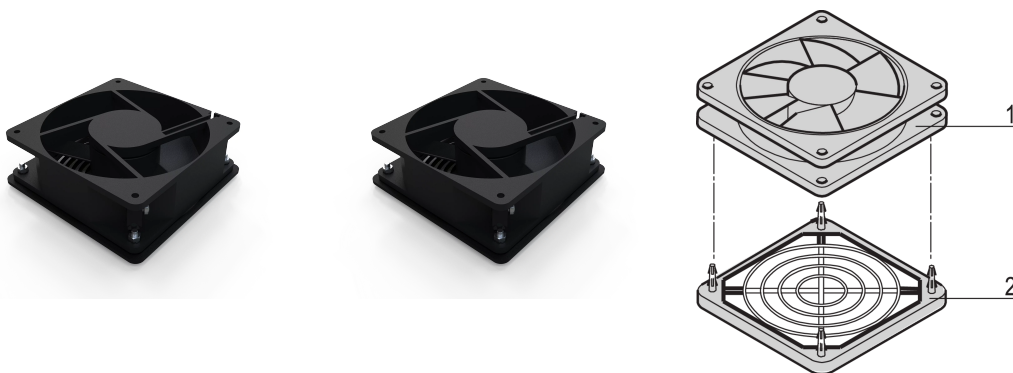

Top covers with fans are compact active cooling units which do not consume rack space. The Varistar fan for top cover comes with high specifications.

FEATURES

Varistar Top Cover Fan, Height 38 mm, 171 m³/h

PRODUCT ATTRIBUTES

Product Type: Fan

Product Family: Varistar CP

Works With: Varistar CP

Глубина мм: 119mm

Noise Level: 42.5dB(A)

Мощность W: 9.6W

Max Static Pressure: 68.1Pa

Airflow @ 50 Hz: 171m³/h

Finish: Powder Coated

Высота мм: 38mm

Input Voltage AC: 18 – 27.6V

Material: Сталь

Net Weight: 0.315kg

Package Quantity: 1

Ширина мм: 119mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE