


Горизонтальная рейка, задняя, тип Н-VT, усиленная, 84 НР

CATALOG NUMBER

34560-784

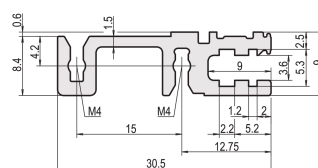

Combinations of horizontal rails and side panels

	"A" can be combined		"A" combination not recommended		
Extruded T		-	+	+	Advised to support
Recessed T		+	Advised to flexibly fix the connection	Advised to flexibly and permanently secure	Advised to support
Light T		Advised to fix rigid	Advised to flexibly	-	-
Perforated (H)		+	+	-	-
Side panel					
	Light T	Recessed T	Heavy T	Extruded T	

Горизонтальная рейка, тип VT, обеспечивает прямой монтаж объединительной платы.

CERTIFICATIONS



FEATURES

Для прямого монтажа объединительной платы

Установка сверху и снизу

Заглубленный монтаж для высоких механических нагрузок (H-VT)

Алюминиевый экструдированный профиль, анодированная поверхность, электропроводящая контактная поверхность

PRODUCT ATTRIBUTES

Rack Width: 84HP

Ширина мм: 431.8mm

Package Quantity: 1

Глубина мм: 30.5mm

Finish: Anodized

Высота мм: 9mm

Длина мм: 431.8mm

Material: Алюминий

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Горизонтальный рельс

Type: Heavy, VT

Works With: Блочный каркас; Coffrets

ADDITIONAL PRODUCT DETAILS

Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE