


Передняя ручка, цельная, ширина 12,2 мм

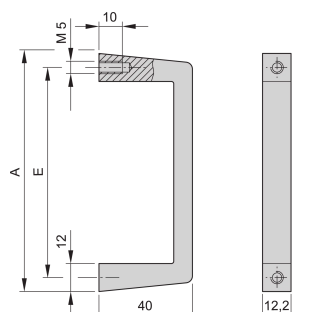

Ручка может крепиться к блочному каркасу или 19-дюймовой передней панели. Поставляется с прозрачным или черным анодным покрытием. Ручки крепятся болтами с задней стороны.

CERTIFICATIONS



FEATURES

Допустимая статическая нагрузка 30 кг/пара

Привинчивается сзади

SPECIFICATIONS

Material:	Алюминий
Product Family:	EuropacPRO
Product Type:	Ручка
Works With:	Блочный каркас

Table 1/2

Catalog Number	Rack Height	Finish	Package Quantity	Handle Type	Color	Torque
10501-116	1U	Anodized	1	Straight	Серебристый	
10501-016	2U	Anodized	1	Straight	Серебристый	

CatalogNumber	Rack Height	Finish	Package Quantity	Handle Type	Color	Torque
10501-004	2U	Anodized	1	Straight	Серебристый	
10501-025	2U	Anodized	1	Straight	Черный	
10501-005	3U	Anodized	1	Straight	Серебристый	2.4N·m
10501-020	3U	Anodized	1	Angled Handle	Серебристый	2.4N·m
10501-026	3U	Anodized	1	Straight	Черный	2.4N·m
10501-006	4U	Anodized	1	Straight	Серебристый	
10501-018	4U	Anodized	1	Straight	Серебристый	2.4N·m
10501-021	4U	Anodized	1	Angled Handle	Серебристый	2.4N·m
10501-027	4U	Anodized	1	Straight	Черный	
10501-007	5U	Anodized	1	Straight	Серебристый	
10501-028	5U	Anodized	1	Straight	Черный	
10501-022	6U	Anodized	1	Angled Handle	Серебристый	2.4N·m
10501-008	6U	Anodized	1	Straight	Серебристый	2.4N·m
10501-029	6U	Anodized	1	Straight	Черный	2.4N·m

Table 2/2

Catalog Number	Quick Ship
10501-116	No
10501-016	No
10501-004	No

Catalog Number	Quick Ship
10501-025	No
10501-005	No
10501-020	No
10501-026	No
10501-006	No
10501-018	No
10501-021	No
10501-027	No
10501-007	No
10501-028	No
10501-022	No
10501-008	No
10501-029	No

ADDITIONAL PRODUCT DETAILS

Заказывайте комплект для сборки отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE