

передняя панель, Анодированная с необработанными кромками, Без экранирования



Передняя панель, анодированная с необработанными кромками, без экранирования. Панели позволяют установку на горизонтальные рейки.

CERTIFICATIONS



FEATURES

Неполноразмерная передняя панель, алюминий, 2,5 мм

алюминий, натуральное анодирование, с необработанными краями

SPECIFICATIONS

Глубина мм (D):	2.5mm
Material:	Алюминий
Finish:	Anodized
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель
Type:	Front Panel without Handle

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
----------------	-------------	------------	------------------	-------------	----------	--------------

30810-433	3U	2HP	1	Her	Screw-on Front	Anodized
30818-272	3U	3HP	1	Her	Screw-on Front	Anodized
30818-273	3U	4HP	1	Her	Screw-on Front	Anodized
30818-274	3U	5HP	1	Her	Screw-on Front	Anodized
30818-275	3U	6HP	1	Her	Screw-on Front	Anodized
30818-277	3U	8HP	1	Her	Screw-on Front	Anodized
30818-747	6U	2HP	1	Her	Screw-on Front	Anodized
30818-517	6U	3HP	1	Her	Screw-on Front	Anodized
30818-276	3U	7HP	1	Her	Screw-on Front	Anodized
30818-518	6U	4HP	1	Her	Screw-on Front	Anodized
30818-279	3U	10HP	1	Her	Screw-on Front	Anodized
30818-519	6U	5HP	1	Her	Screw-on Front	Anodized
30818-281	3U	12HP	1	Her	Screw-on Front	Anodized
30818-520	6U	6HP	1	Her	Screw-on Front	Anodized
30818-521	6U	7HP	1	Her	Screw-on Front	Anodized
30818-282	3U	14HP	1	Her	Screw-on Front	Anodized
30818-284	3U	16HP	1	Her	Screw-on Front	Anodized
30818-522	6U	8HP	1	Her	Screw-on Front	Anodized
30818-524	6U	10HP	1	Her	Screw-on Front	Anodized

30818-289	3U	21HP	1	Her	Screw-on Front	Anodized
30818-331	3U	63HP	1	Her	Screw-on Front	Anodized
30818-526	6U	12HP	1	Her	Screw-on Front	Anodized
30818-296	3U	28HP	1	Her	Screw-on Front	Anodized
30818-528	6U	14HP	1	Her	Screw-on Front	Anodized
30818-530	6U	16HP	1	Her	Screw-on Front	Anodized
30818-535	6U	21HP	1	Her	Screw-on Front	Anodized
30818-310	3U	42HP	1	Her	Screw-on Front	Anodized
30818-271	2U	84HP	1	Her	Screw-on Front	Anodized
30818-542	6U	28HP	1	Her	Screw-on Front	Anodized
30818-556	6U	42HP	1	Her	Screw-on Front	Anodized
30818-352	3U	84HP	1	Her	Screw-on Front	Anodized
30818-434	4U	84HP	1	Her	Screw-on Front	Anodized
30818-577	6U	63HP	1	Her	Screw-on Front	Anodized
30818-598	6U	84HP	1	Her	Screw-on Front	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм (W)
30810-433	Anodized	Her	IEC 60297-3-101, IEEE 1101.1/10	Her	128.4mm	9.8mm
30818-272	Anodized	Her	IEC 60297-3-101, IEEE 1101.1/10	Her	128.4mm	14.9mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм(W)
30818-273	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	20mm
30818-274	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	25mm
30818-275	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	30.1mm
30818-277	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	40.3mm
30818-747	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	9.8mm
30818-517	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	14.9mm
30818-276	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	35.2mm
30818-518	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	20mm
30818-279	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	50.5mm
30818-519	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	25mm
30818-281	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	60.6mm
30818-520	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	30.1mm
30818-521	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	35.2mm
30818-282	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	70.8mm
30818-284	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	80.9mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм(W)
30818-522	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	40.3mm
30818-524	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	50.5mm
30818-289	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	106.3mm
30818-331	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	319.7mm
30818-526	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	60.6mm
30818-296	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	141.9mm
30818-528	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	70.8mm
30818-530	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	80.9mm
30818-535	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	106.3mm
30818-310	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	213mm
30818-271	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	84mm	426.4mm
30818-542	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	141.9mm
30818-556	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	213mm
30818-352	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4mm	426.4mm
30818-434	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	172.9mm	426.4mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм(W)
30818-577	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	319.7mm
30818-598	Anodized	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8mm	426.4mm

Table 3/3

Catalog Number	Certifications	Quick Ship
30810-433	RoHS	No
30818-272	RoHS	No
30818-273	RoHS	No
30818-274	RoHS	No
30818-275	RoHS	No
30818-277	RoHS	No
30818-747	RoHS	No
30818-517		No
30818-276	RoHS	No
30818-518	RoHS	No
30818-279	RoHS	No
30818-519	RoHS	No
30818-281	RoHS	No
30818-520	RoHS	No
30818-521	RoHS	No


Catalog Number	Certifications	Quick Ship
30818-282	RoHS	No
30818-284		No
30818-522	RoHS	No
30818-524	RoHS	No
30818-289	RoHS	No
30818-331	RoHS	No
30818-526	RoHS	No
30818-296	RoHS	No
30818-528	RoHS	No
30818-530	RoHS	No
30818-535	RoHS	No
30818-310	RoHS	No
30818-271	RoHS	No
30818-542	RoHS	No
30818-556	RoHS	No
30818-352	RoHS	No
30818-434	RoHS	No
30818-577	RoHS	No

Catalog Number	Certifications	Quick Ship
30818-598	RoHS	No

ADDITIONAL PRODUCT DETAILS

Крепежный материал (втулки, винты с проточкой) заказывается отдельно.

DIAGRAMS

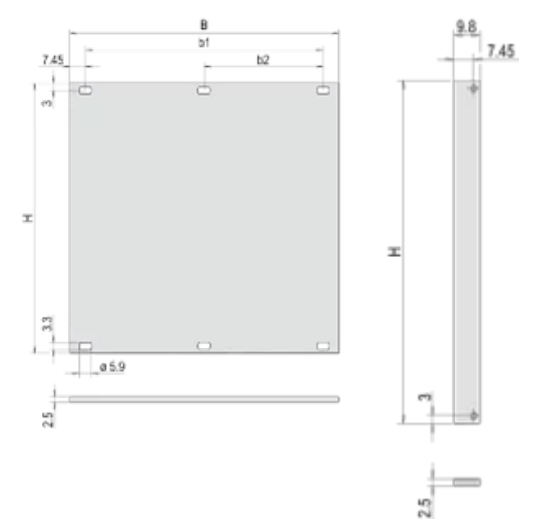

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE