


# передняя панель, плоская, возможно дооснащение экранированием, Вырезы D-Sub

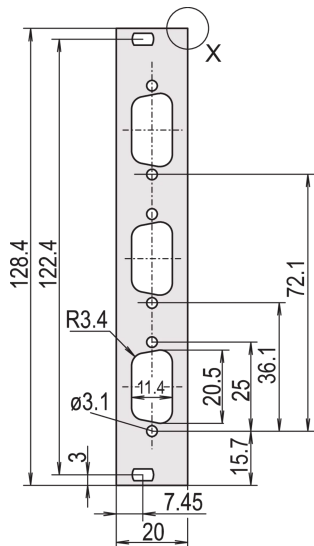

Плоская передняя панель с вырезом для разъемов D-Sub. Возможность экранирования ЭМС-прокладкой из нержавеющей стали.

## CERTIFICATIONS



## FEATURES

Для ЭМС-прокладки из нержавеющей стали

алюминий, 2,5 мм, лицевая поверхность анодированная, токопроводящая

## SPECIFICATIONS

|                       |                      |
|-----------------------|----------------------|
| <b>Rack Height:</b>   | 3U                   |
| <b>Rack Width:</b>    | 4HP                  |
| <b>Material:</b>      | Алюминий             |
| <b>Finish:</b>        | Anodized; Passivated |
| <b>Аксессуар Тип:</b> | Передняя панель      |

**Product Type:** Передняя панель  
**Type:** Front Panel without Handle  
**EMC Shielding:** No (Retrofittable)





Table 1/2

| Catalog Number | Package Quantity | Mounting       | EMC Gasket Type   | Front Finish | Rear Finish | Number of Pins |
|----------------|------------------|----------------|-------------------|--------------|-------------|----------------|
| 30118-348      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (1) 9          |
| 30118-349      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (1) 15         |
| 30118-350      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (1) 25         |
| 30118-351      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (2) 9          |
| 30118-352      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (2) 15         |
| 30118-353      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (2) 25         |
| 30118-354      | 1                | Screw-on Front | Нержавеющая сталь | Anodized     | Conductive  | (3) 9          |

Table 2/2

| Catalog Number | Treated Edges | Complies With                   | Глубина мм (D) | Высота мм (H) | Ширина мм (W) | Quick Ship |
|----------------|---------------|---------------------------------|----------------|---------------|---------------|------------|
| 30118-348      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |
| 30118-349      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |
| 30118-350      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |
| 30118-351      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |
| 30118-352      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |
| 30118-353      | Нет           | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm          | 128.4mm       | 19.98mm       | No         |



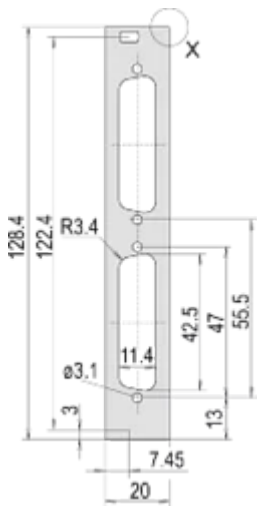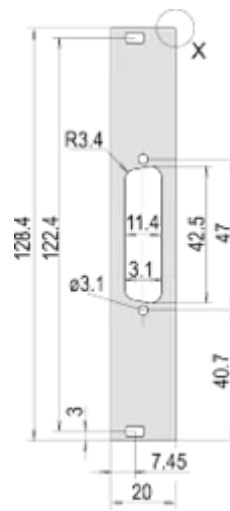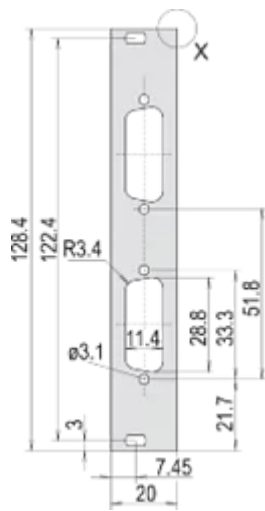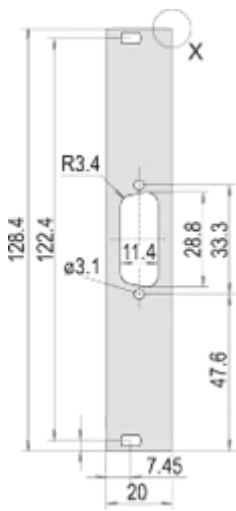

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void any warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**