


Guide Rail With Coding, preassembled ESD Clip for CompactPCI/ VME64x, PC

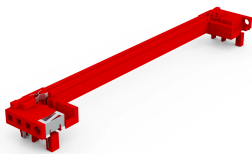

CERTIFICATIONS



FEATURES

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPECIFICATIONS

Works With:	Блочный каркас; Coffrets; 19" Chassis; Системы
Type:	Coding and Preassembled ESD Clips
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Material:	Fiber-Reinforced Plastic
Product Type:	Направляющие рельсы

Table 1/2

Catalog Number	Color	Package Quantity	Board Depth	Groove Width	Complies With	Rail Type
24568-853	Красный	10	70mm	2	EN 45545-2	Top
24568-855	Красный	10	70mm	2	EN 45545-2	Bottom
24568-854	Серый	10	70mm	2	EN 45545-2	Top
24568-856	Серый	10	70mm	2	EN 45545-2	Bottom
24568-847	Красный	10	160mm	2	EN 45545-2	Bottom
24568-850	Красный	10	160mm	2	EN 45545-2	Top
24568-848	Серый	10	160mm	2	EN 45545-2	Bottom
24568-851	Серый	10	160mm	2	EN 45545-2	Top

Table 2/2

Catalog Number	Quick Ship
24568-853	No
24568-855	No
24568-854	No
24568-856	No
24568-847	No
24568-850	No
24568-848	No
24568-851	No

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE