


Базовый комплект для 19-дюймового шасси MultipacPRO

Такой набор позволяет заказчику конфигурировать 3 различных верхних/нижних крышек.

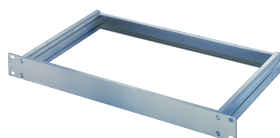

CERTIFICATIONS



FEATURES

Для нестандартизированных модулей (1 ... 5 U) и стандартизированных модулей (1, 2 U), отвечающих требованиям IEC 60297-3-105

Рама состоит из двух боковых частей и передней/задней панели

Материал: алюминий

Выбор отдельных элементов конструктива (принадлежности)

SPECIFICATIONS

Material:	Алюминий
Type:	Configurable
Product Family:	MultipacPRO
EMC Shielding:	No (Retrofittable)
Product Type:	Subrack/Chassis

Table 1/2

Catalog Number	Rack Height	Глубина мм	Usable Width	Mounting	Complies With	Certifications
----------------	-------------	------------	--------------	----------	---------------	----------------

20860-201	1U	220mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-202	1U	280mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-203	1U	340mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-204	1U	400mm	403mm	Rack	IEC 60297-3-100	
20860-205	1U	460mm	403mm	Rack	IEC 60297-3-100	
20860-210	2U	220mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-231	4U	460mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-211	2U	280mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-212	2U	340mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-213	2U	400mm	403mm	Rack	IEC 60297-3-100	
20860-214	2U	460mm	403mm	Rack	IEC 60297-3-100	
20860-219	3U	280mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-220	3U	340mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-221	3U	400mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-228	4U	280mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-222	3U	460mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-229	4U	340mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-230	4U	400mm	403mm	Rack	IEC 60297-3-100	RoHS
20860-240	5U	460mm	403mm	Rack	IEC 60297-3-100	RoHS

Table 2/2

Catalog Number	Quick Ship
20860-201	No
20860-202	No
20860-203	No
20860-204	No
20860-205	No
20860-210	No
20860-231	No
20860-211	No
20860-212	No
20860-213	No
20860-214	No
20860-219	No
20860-220	No
20860-221	No
20860-228	No
20860-222	No
20860-229	No
20860-230	No

Catalog Number	Quick Ship
20860-240	No

ADDITIONAL PRODUCT DETAILS

Монтажная панель, крышка и панели основания, ручки, телескопические направляющие заказываются отдельно.

Размеры h = чистая монтажная высота = H-8,1 мм, b = чистая ширина монтажа = 403 мм.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE