


Ручка MultipacPRO, цельная, ширина 10 мм

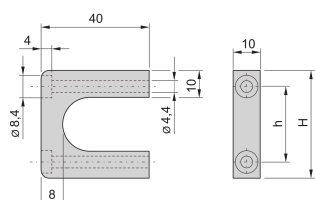

Монтаж передних ручек обеспечивает более легкую сборку. Ручки можно смонтировать с передней стороны.

CERTIFICATIONS



FEATURES

Допустимая нагрузка 30 кг/пара

Монтаж на передней панели

Может использоваться для вариантов исполнения из алюминия или листового металла

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized
Works With:	Chassis; Передние панели
Product Family:	MultipacPRO; Frame Type Plug-In Unit
Product Type:	Ручка

Table 1/1

Catalog Number	Rack Height	Package Quantity	Handle Type	Color	Ширина мм	Quick Ship
20860-256	1U	2	Straight	Серебристый	10mm	No
20860-257	2U	2	Straight	Серебристый	10mm	No

CatalogNumber	Rack Height	Package Quantity	Handle Type	Color	Ширина мм	Quick Ship
20860-259	4U	2	Straight	Серебристый	10mm	No
20860-258	3U	2	Straight	Серебристый	10mm	No
20860-260	5U	2	Straight	Серебристый	10mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE