


19-дюймовая панель/монтажный профиль Novastar

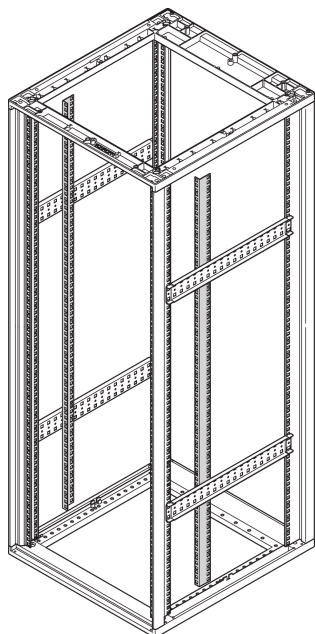

19-дюймовый монтажный комплект Novastar для панелей/направляющих с нагрузочной способностью 400 кг обеспечивает удобное крепление 19-дюймовых компонентов на заглубляющих распорках.

CERTIFICATIONS



FEATURES

Для углубленного монтажа 19-дюймовых компонентов

Для установки на заглубляющих распорках (сетка 25 мм)

Допустимая нагрузка 400 кг

SPECIFICATIONS

Product Type: Slide Mount

Material: Сталь

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Finish	Высота мм
27230-172	6U	2	Black Grey	RAL 7021	Powder Coated	267.1mm
27230-173	9U	2	Black Grey	RAL 7021	Powder Coated	400.45mm
27230-174	12U	2	Black Grey	RAL 7021	Powder Coated	533.8mm
27230-175	16U	2	Black Grey	RAL 7021	Powder Coated	711.6mm
27230-176	20U	2	Black Grey	RAL 7021	Powder Coated	889.4mm
27230-177	25U	2	Black Grey	RAL 7021	Powder Coated	1111.65mm
27230-197	29U	2	Black Grey	RAL 7021	Powder Coated	1291mm
27230-178	34U	2	Black Grey	RAL 7021	Powder Coated	1511.7mm
27230-179	38U	2	Black Grey	RAL 7021	Powder Coated	1689.5mm
27230-180	43U	2	Black Grey	RAL 7021	Powder Coated	1911.75mm
27230-181	47U	2	Black Grey	RAL 7021	Powder Coated	2089.55mm

Table 2/2

Catalog Number	Package Unit	Certifications	Quick Ship
27230-172	Pair	RoHS	No
27230-173	Pair	RoHS	No
27230-174	Pair	RoHS	No
27230-175	Pair	RoHS	No
27230-176	Pair	RoHS	No

Catalog Number	Package Unit	Certifications	Quick Ship
27230-177	Pair	RoHS	No
27230-197			No
27230-178	Pair	RoHS	No
27230-179	Pair	RoHS	No
27230-180	Pair	RoHS	No
27230-181	Pair	RoHS	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE