


# 19-дюймовая полка Novastar, стационарная

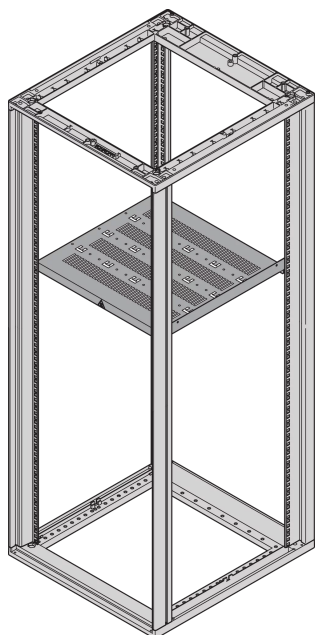

19-дюймовая полка Novastar, стационарная, с несущей способностью 75 кг, перфорированная для удобства сборки.

## CERTIFICATIONS



## FEATURES

Монтажная высота 1 U, для установки на вертикальные стойки шкафа

Допустимая статическая нагрузка 75 кг

Со специальной перфорацией для крепления кабельных хомутов

Сталь, 1,5 мм

С перфорацией

Цвет RAL 7021

## SPECIFICATIONS

**Product Type:** Полка с креплением на каркасе

**Material:** Сталь

Table 1/2

| Catalog Number | Ширина мм | Глубина мм | Package Quantity | Color      | Color Code | Finish        |
|----------------|-----------|------------|------------------|------------|------------|---------------|
| 27230-051      | 553mm     | 500mm      | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-165      | 740mm     | 900mm      | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-089      | 553mm     | 1000mm     | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-053      | 553mm     | 800mm      | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-088      | 553mm     | 900mm      | 1                | Black Grey | RAL 7021   | Powder Coated |
| 27230-052      | 553mm     | 600mm      | 1                | Black Grey | RAL 7021   | Powder Coated |

Table 2/2

| Catalog Number | Высота мм | Type             | Quick Ship |
|----------------|-----------|------------------|------------|
| 27230-051      | 44.45mm   | Stationary Shelf | No         |
| 27230-165      | 44.45mm   | Stationary Shelf | No         |
| 27230-089      | 44.45mm   | Stationary Shelf | No         |
| 27230-053      | 44.45mm   | Stationary Shelf | No         |
| 27230-088      | 44.45mm   | Stationary Shelf | No         |
| 27230-052      | 44.45mm   | Stationary Shelf | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**