

Комплект вставного модуля с ручкой IEL для задней панели ввода/вывода, с экранированием, черный



Сменный модуль, с черной ручкой IEL для устройства для вставки/извлечения, 3 U, монтаж на задней панели ввода-вывода. U-образная передняя панель обеспечивает экранирование с помощью текстильного уплотнителя.

CERTIFICATIONS



FEATURES

U-образная передняя панель для текстильного уплотнителя

Подходит для нагрузок вставки и извлечения до 700 Н (на пару ручек)

Позволяет выполнить установку микропереключателя

Позволяет выполнить установку кодированных штекеров в соответствии с IEC 60297-3-103/ IEEE 1101.10

SPECIFICATIONS

Rack Height:	3U
Material:	Алюминий
Finish:	Anodized; Passivated
Product Type:	Передняя панель
Type:	Front Panel with Handle (PIU)
EMC Shielding:	Да


Table 1/2

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
20848-751	4HP	1	IEL	Screw-on Rear IO	Textile EMC	Anodized
20848-752	8HP	1	IEL	Screw-on Rear IO	Textile EMC	Anodized

Table 2/2

Catalog Number	Rear Finish	Treated Edges	Complies With	Высота мм (H)	Ширина мм (W)	Quick Ship
20848-751	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	128.4mm	20mm	No
20848-752	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	128.4mm	40.3mm	No

DIAGRAMS

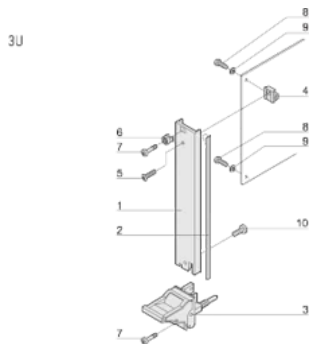

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE