

# Комплект вставного модуля с трапецевидной ручкой, с экранированием, серый



Сменный модуль со статичной ручкой и U-образной передней панелью. Серая ручка собрана на передней панели. На U-образной панели возможна сборка текстильного уплотнителя.

## CERTIFICATIONS



## FEATURES

Передняя панель, U-образный профиль, экранированный

Ручка без функции извлечения

## SPECIFICATIONS

|                       |                               |
|-----------------------|-------------------------------|
| <b>Material:</b>      | Алюминий                      |
| <b>Finish:</b>        | Anodized; Passivated          |
| <b>Product Type:</b>  | Передняя панель               |
| <b>Type:</b>          | Front Panel with Handle (PIU) |
| <b>EMC Shielding:</b> | Да                            |

Table 1/3

| Catalog Number | Rack Height | Rack Width | Package Quantity | Handle Type | Mounting | EMC Gasket Type |
|----------------|-------------|------------|------------------|-------------|----------|-----------------|
|----------------|-------------|------------|------------------|-------------|----------|-----------------|

|           |    |      |   |                                     |                |         |
|-----------|----|------|---|-------------------------------------|----------------|---------|
| 20848-663 | 3U | 3HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-664 | 3U | 4HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-665 | 3U | 5HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-666 | 3U | 6HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-667 | 3U | 7HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-668 | 3U | 8HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-669 | 3U | 10HP | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-671 | 6U | 3HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-670 | 3U | 12HP | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-672 | 6U | 4HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-675 | 6U | 7HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-673 | 6U | 5HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-674 | 6U | 6HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-676 | 6U | 8HP  | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
| 20848-677 | 6U | 10HP | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |

|           |    |      |   |                                     |                |         |
|-----------|----|------|---|-------------------------------------|----------------|---------|
| 20848-678 | 6U | 12HP | 1 | Трапецевидной ручкой, антистатическ | Screw-on Front | Textile |
|-----------|----|------|---|-------------------------------------|----------------|---------|

Table 2/3

| Catalog Number | Front Finish | Rear Finish | Treated Edges | Flammability Rating | Complies With                             | Высота мм (H) |
|----------------|--------------|-------------|---------------|---------------------|-------------------------------------------|---------------|
| 20848-663      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-664      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-665      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-666      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-667      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-668      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-669      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-671      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-670      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 128.4mm       |
| 20848-672      | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |


| CatalogNumber | Front Finish | Rear Finish | Treated Edges | Flammability Rating | Complies With                             | Высота мм (H) |
|---------------|--------------|-------------|---------------|---------------------|-------------------------------------------|---------------|
| 20848-675     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-673     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-674     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-676     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-677     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |
| 20848-678     | Anodized     | Etched      | Нет           | UL® 94V-0           | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | 261.8mm       |

Table 3/3

| Catalog Number | Ширина мм (W) | Quick Ship |
|----------------|---------------|------------|
| 20848-663      | 14.9mm        | No         |
| 20848-664      | 20mm          | No         |
| 20848-665      | 25mm          | No         |
| 20848-666      | 30.1mm        | No         |
| 20848-667      | 35.2mm        | No         |
| 20848-668      | 40.3mm        | No         |
| 20848-669      | 50.5mm        | No         |

| Catalog Number | Ширина мм (W) | Quick Ship |
|----------------|---------------|------------|
| 20848-671      | 14.9mm        | No         |
| 20848-670      | 60.6mm        | No         |
| 20848-672      | 20mm          | No         |
| 20848-675      | 35.2mm        | No         |
| 20848-673      | 25mm          | No         |
| 20848-674      | 30.1mm        | No         |
| 20848-676      | 40.3mm        | No         |
| 20848-677      | 50.5mm        | No         |
| 20848-678      | 60.6mm        | No         |

## DIAGRAMS

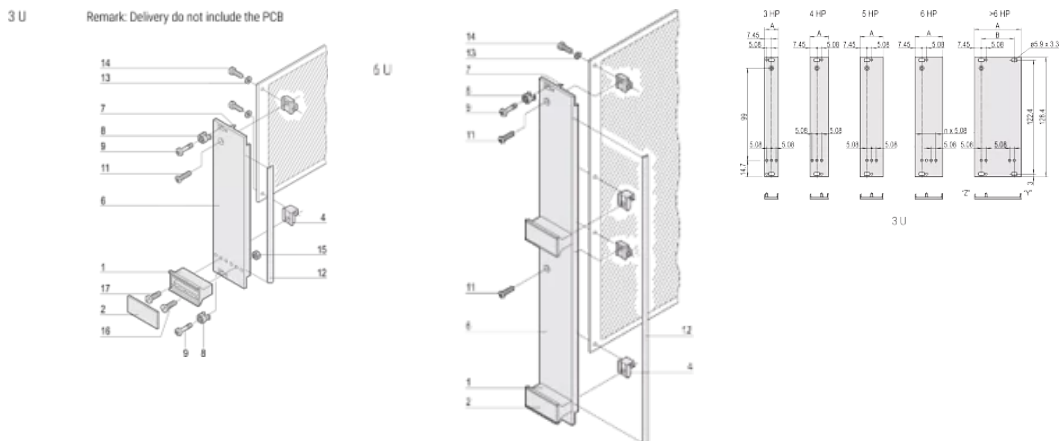

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**