


PSU Front Panel

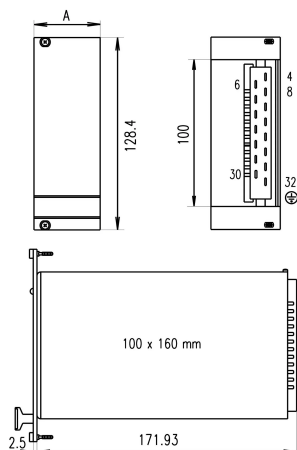

Передняя панель для источника питания, совместимого с 19-дюймовым решением nVent SCHROFF. Плоская передняя панель с вертикальными канавками для контактных лент ЭМС из нержавеющей стали.

CERTIFICATIONS



FEATURES

передняя панель, алюминий, лицевая поверхность анодированная, тыльная поверхность электропроводящая, С вертикальными слотами для контактных лент ЭМС

SPECIFICATIONS

Аксессуар Тип: Передняя панель

Table 1/2

Catalog Number	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Высота мм
21006-959	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21006-955	Алюминий	Anodized	Conductive	Нет	3U	128.4mm

CatalogNumber	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Высота мм
21006-957	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21006-943	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21006-954	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21006-956	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-476	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21006-945	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-475	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
31006-677	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-470	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-477	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-473	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-451	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-439	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-474	Алюминий	Anodized	Conductive	Нет	3U	128.4mm
21005-478	Алюминий	Anodized	Conductive	Нет	3U	128.4mm

Table 2/2

Catalog Number	Rack Width	Ширина мм	Глубина мм	Package Quantity	Finish	Quick Ship
21006-959	3HP	14.9mm	2.5mm	1	Anodized	No
21006-955	6HP	30.14mm	2.5mm	1	Anodized	No

CatalogNumber	Rack Width	Ширина мм	Глубина мм	Package Quantity	Finish	Quick Ship
21006-957	6HP	30.14mm	2.5mm	1	Anodized	No
21006-943	6HP	30.14mm	2.5mm	1	Anodized	No
21006-954	6HP	30.14mm	2.5mm	1	Anodized	No
21006-956	6HP	30.14mm	2.5mm	1	Anodized	No
21005-476	6HP	30.14mm	2.5mm	1	Anodized	No
21006-945	8HP	40.3mm	2.5mm	1	Anodized	No
21005-475	6HP	30.14mm	2.5mm	1	Anodized	No
31006-677	8HP	40.3mm	2.5mm	1	Anodized	No
21005-470	6HP	30.14mm	2.5mm	1	Anodized	No
21005-477	10HP	50.46mm	2.5mm	1	Anodized	No
21005-473	10HP	50.46mm	2.5mm	1	Anodized	No
21005-451	10HP	50.46mm	2.5mm	1	Anodized	No
21005-439	14HP	70.78mm	2.5mm	1	Anodized	No
21005-474	14HP	70.78mm	2.5mm	1	Anodized	No
21005-478	14HP	70.78mm	2.5mm	1	Anodized	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE