


Блок радиального вентилятора RatiopacPRO Air

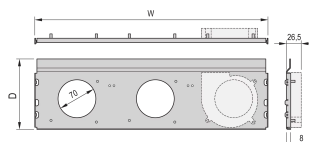

Блок радиального вентилятора для системы RatiopacPRO AIR –простота установки, производительность по воздуху 36 м³/ч (свободное нагнетание) на вентилятор. Доступен в 4 вариантах ширины и 2 вариантах глубины с установкой до 3 вентиляторов.

CERTIFICATIONS



FEATURES

Радиальные вентиляторы на шариковых подшипниках

Производительность по воздуху 36 м³/ч (свободное нагнетание) на вентилятор

Подходит для корпусов RatiopacPRO Air (для блока вентилятора требуется только высота 0,5 U)

Высота только 1/2 U

Выпуск воздуха через перфорацию в заглушке

Нет ограничений по заднему монтажному пространству

Механическая модификация корпуса не требуется

Простота установки

SPECIFICATIONS

Material:	Алюминий
Works With:	Coffrets
Product Type:	Fan
Type:	Radial Fan
Product Family:	RatiopacPRO AIR

Table 1/1

Catalog Number	Rack Width	Voltage DC	Airflow	Глубина мм	Ширина мм	Quick Ship
----------------	------------	------------	---------	------------	-----------	------------

24572-408	28HP	12V	36m³/h	220mm	146.87mm	No
24572-405	42HP	12V	36m³/h	160mm	218mm	No
24572-409	42HP	12V	36m³/h	220mm	218mm	No
24572-406	63HP	12V	36m³/h	160mm	324.67mm	No
24572-410	63HP	12V	36m³/h	220mm	324.67mm	No
24572-407	84HP	12V	36m³/h	160mm	431.35mm	No
24572-411	84HP	12V	36m³/h	220mm	431.35mm	No
24572-404	28HP	12V	36m³/h	160mm	146.87mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE