
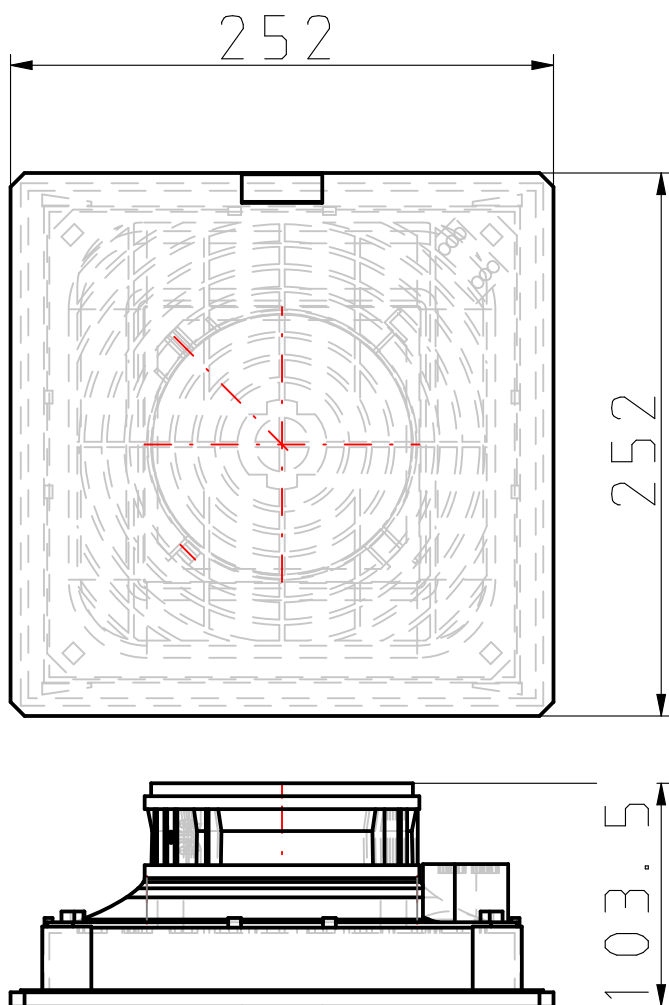


ITEM (Item no.)	EF250-115R5
DETAIL ()	low
INFO (Info PDF)	Info PDF
DES (Description)	Filter Fan Air flow 171 m ³ /h
MAT (Material)	Thermoplastic
OV (Operating voltage)	115 V AC, 50/60Hz
IP (Protection)	IP 54 TYPE 12
BT (Bearing type)	Sleeve
CON (Connection)	Spring type
I (Current / A)	0.25/0.25
N (Noise / dB)	40
FAF (Free air flow / m ³ /h)	171
AF (EF+EFA Air flow / m ³ /h)	93/102
CONT (Connection Type)	3
UA (Unimpeded airflow / m ³ /h)	125/138
FM (Filter mat / EN779)	G4
FE (Filtration efficiency / %)	>90
SE (Service life L10 / hl)	42 500
CO (Cut-out / mm)	223 x 223
PO (Power / W)	18/17

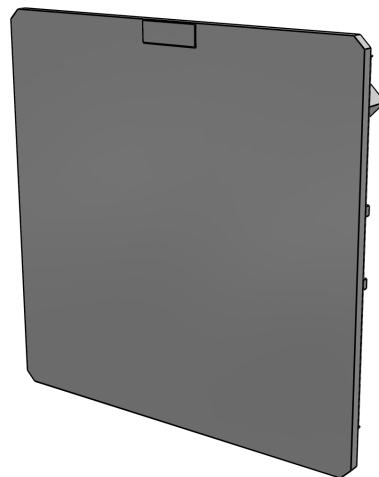

CE EAC