


Pipe to Rigid Conduit Ground Clamp

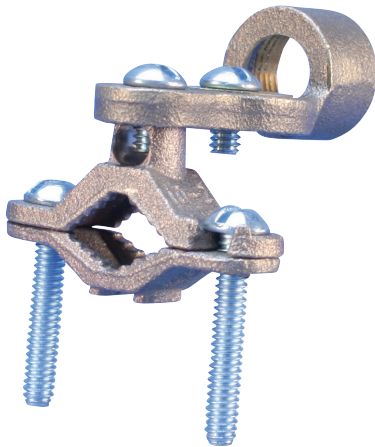

The nVent ERICO Pipe to Rigid Conduit Ground Clamp is constructed from durable bronze material and engineered to provide a secure and reliable electrical grounding connection between a metallic water pipe and rigid conduit systems.


FEATURES

- Ensures a secure mechanical and electrical connection for system grounding
- Available in various sizes to accommodate common water pipe and rigid conduit dimensions

Material: Bronze

Part Number	Pipe Size, Nominal Ø	Ground Rod Diameter, Actual Ø	Water Pipe Size Ø	Rebar Size, US	Tap Conductor Range	Conductor Size	Conductor Material	Rigid Conduit Size	Number of Conductors	Complies With
BGC-1-10S	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	1	1	UL® 467
BGC-1-10SH	0.5" – 1"	–	–	–	2/0 – 10 AWG	–	Copper	1	1	UL® 467
BGC-1-50S	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	½	1	UL® 467
BGC-1-50SH	0.5" – 1"	–	–	–	2/0 – 10 AWG	–	Copper	½	1	UL® 467
BGC-1-75S	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	¾	1	UL® 467
BGC-1-75SH	0.5" – 1"	–	–	–	2/0 – 10 AWG	–	Copper	¾	1	UL® 467
BGC-1DB	0.5" – 1"	–	–	–	2 – 10 AWG	–	Copper	–	–	UL® 467
BGC-2	1.25" – 2"	–	–	–	2 – 10 AWG	–	Copper	–	1	UL® 467
BGC-2A	1.25" – 2"	–	–	–	4 – 8 AWG	–	Copper	–	1	UL® 467
BGC-2DB	1.25" – 2"	–	–	–	2 – 10 AWG	–	Copper	–	1	UL® 467
BGC-2P-DB	0.5" – 1"	0.5" – 1"	–	#3 – #8	2 – 10 AWG	–	Copper	–	–	UL® 467
BGC-2PS-DB	0.5" – 1"	0.25" – 1"	–	#3 – #8	2 – 10 AWG	–	Copper	–	–	UL® 467
BGC1-10	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	1	1	UL® 467
BGC1-50	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	½	1	UL® 467
BGC1-75	0.5" – 1"	–	–	–	4 – 8 AWG	–	Copper	¾	1	UL® 467
BGC2-10	1.25" – 2"	–	–	–	4 – 8 AWG	–	Copper	1	1	UL® 467
BGC2-50	1.25" – 2"	–	–	–	4 – 8 AWG	–	Copper	½	1	UL® 467
BGC2-75	1.25" – 2"	–	–	–	4 – 8 AWG	–	Copper	¾	1	UL® 467
CH-1	–	–	–	–	3/0 – 10 AWG	–	Copper	1	1	UL® 467
CH-34	–	–	–	–	2/0 – 10 AWG	–	Copper	¾	1	UL® 467

Part Number	Pipe Size, Nominal Ø	Ground Rod Diameter, Actual Ø	Water Pipe Size Ø	Rebar Size, US	Tap Conductor Range	Conductor Size	Conductor Material	Rigid Conduit Size	Number of Conductors	Complies With
CWP1JH12	—	—	½" – 1"	—	—	#10 Solid – #6 Solid	—	½"	—	—
CWP1JH34	—	—	½" – 1"	—	—	#10 Solid – 2/0 Stranded	—	¾"	—	—
CWP2JH34	—	—	1¼" – 2"	—	—	#10 Solid – 2/0 Stranded	—	¾"	—	—
CWP2JH44	—	—	1¼" – 2"	—	—	#10 Solid – 3/0 Stranded	—	1	—	—
CWP4JH34	—	—	2½" – 4"	—	—	#10 Solid – 2/0 Stranded	—	¾"	—	—
J2124	2.5" – 4"	—	—	—	4 – 10 AWG	—	Copper	—	—	UL® 467

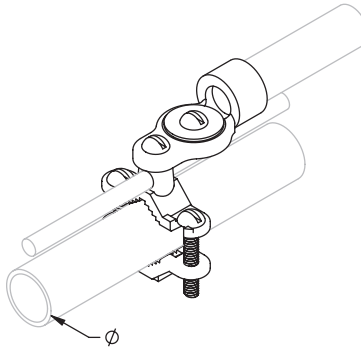

Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE