

# nVent CADDY CATHP J-Hook

## Features Guide




### ROBUST CONSTRUCTION

- Class leading load capacity
- UL2239 – 60 lbs
- Design feature for simple field configurations, UL listed



### CABLE SUPPORT & PROTECTION

- Generous bend radius
- Meets latest TIA-568 requirements
- Future proof installations for ultra-high speed and PoE

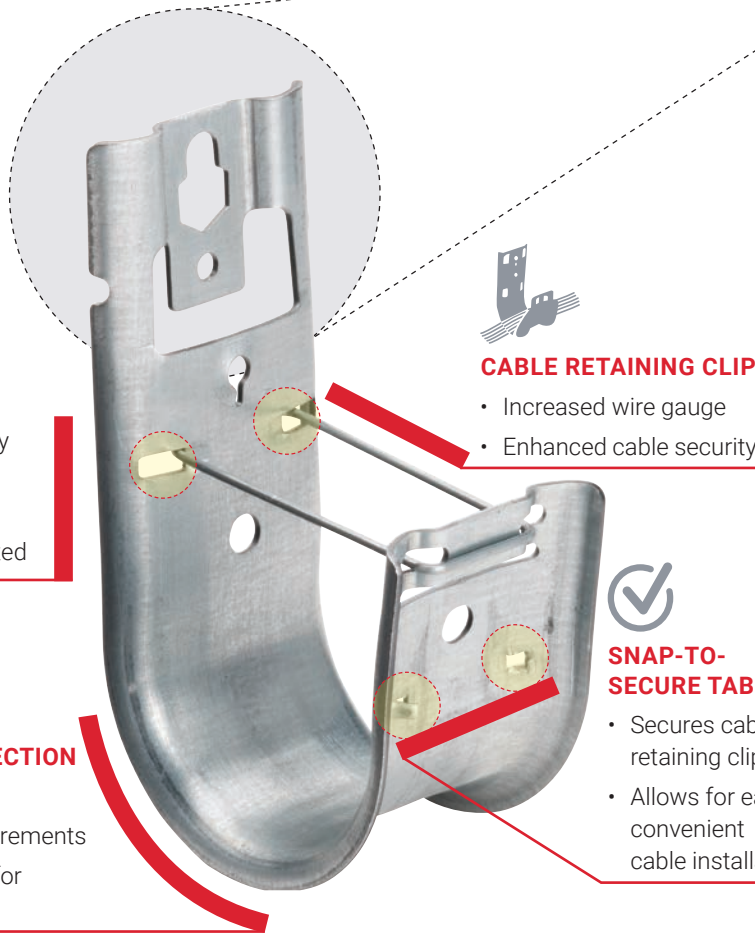

### CABLE RETAINING CLIP

- Increased wire gauge
- Enhanced cable security




### SNAP-TO-SECURE TABS

- Secures cable retaining clip
- Allows for easy, convenient cable installation

## VERSA-MOUNT TECHNOLOGY

The nVent CADDY J-Hook Versa-Mount Technology is an innovative attachment design that provides multiple structural and installation methods for wall, ceiling, and threaded rod mounting applications.

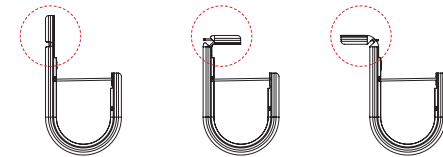

### Wall mount:

- Flat flush mount allows for no gap between wall upon install
- Hex feature allows for pre-installed fastener
- Allows for multiple types of hardware, including shot fire



### Threaded rod mount:

- 1/4" & 3/8"
- Quickly and easily bend hook for field install
- Use SN25 or SN38 for quick, simple securement to threaded rod



### Ceiling/deck mount:

- Use commercially available shot fire (pins not included)
- Pin geometry minimizes prying effect during cable installation
- Quickly and easily bend hook for field install

