

Wall-Mount Enclosures and Accessories

Continuous Hinge with Clamps, Type 4X



SPECIFICATIONS

- 14 gauge Type 304 or Type 316L stainless steel bodies and doors
- Seams continuously welded and ground smooth
- Seamless foam-in-place gasket
- Rolled lip around three sides of door
- Stainless steel door clamp assembly
- Hasp and staple for padlocking
- Door removed by pulling stainless steel continuous hinge pin
- Data pocket is high-impact thermoplastic
- Collar studs provided for mounting optional panels
- Exterior hardware on Type 316L stainless steel enclosures matches enclosure material
- Bonding provision on door; grounding stud on body
- Type 4X and offshore models Stainless Steel 316L

ACCESSORIES

Fast-Operating Clamp Assembly

Panels for Type 3R, 4, 4X, 12 and 13 Enclosures

Junction Box and Wall-Mount Enclosure Swing Out Panel Kit

Steel and Stainless Steel Window Kits

H2OMIT Vent Drains, Type 4X

H2OMIT Thermoelectric Dehumidifier

MODIFICATION AND CUSTOMIZATION

nVent HOFFMAN excels at modifying and customizing products to your specifications. Contact your local nVent HOFFMAN sales office or distributor for complete information.

BULLETIN: A4S

INDUSTRY STANDARDS

UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997
cUL Listed per CSA C22.2 No 94; Type 3R, 4, 4X, 12;
File No. E61997

NEMA/EEMAC Type 3, 3R, 4, 4X, 12, 13

IEC 60529, IP66

Meets NEMA Type 3RX requirements

APPLICATION

For use in indoor and outdoor corrosive environments that require a water-tight seal, this enclosure's seamless foam-in-place gasket and screw-down clamps provide a secure seal against contaminants.


STANDARD PRODUCT

Catalog Number	Article Number	Height (mm)	Width (mm)	Depth (mm)	Material	Thickness (mm)	Panel Size (mm)	Steel Panel	Data Pocket	Conductive Steel Panel	Stainless Steel Panel	Clamp Quantity
A16H1206SSLP	24050	406	305	152	Stainless Steel 304	1.98	330 × 229	A16P12	Small	A16P12G	A16P12SS6	2
A16H1206SS6LP	29080	406	305	152	Stainless Steel 316L	1.98	330 × 229	A16P12	Small	A16P12G	A16P12SS6	2
A16H1606SSLP	24060	406	406	152	Stainless Steel 304	1.98	330 × 330	A16P16	Small	A16P16G	A16P16SS6	2
A16H1606SS6LP	83560	406	406	152	Stainless Steel 316L	1.98	330 × 330	A16P16	Small	A16P16G	A16P16SS6	2
A16H2006SSLP	29050	406	508	152	Stainless Steel 304	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A16H2006SS6LP	83550	406	508	152	Stainless Steel 316L	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H1606SSLP	24070	508	406	152	Stainless Steel 304	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H1606SS6LP	29090	508	406	152	Stainless Steel 316L	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H2006SSLP	24080	508	508	152	Stainless Steel 304	1.98	432 × 432	A20P20	Small	A20P20G	A20P20SS6	2
A20H2006SS6LP	83570	508	508	152	Stainless Steel 316L	1.98	432 × 432	A20P20	Small	A20P20G	A20P20SS6	2
A24H2006SSLP	24090	610	508	152	Stainless Steel 304	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A24H2006SS6LP	83580	610	508	152	Stainless Steel 316L	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A24H2406SSLP	11091	610	610	152	Stainless Steel 304	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A24H2406SS6LP	83590	610	610	152	Stainless Steel 316L	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A16H1208SSLP	24020	406	305	203	Stainless Steel 304	1.98	330 × 229	A16P12	Small	A16P12G	A16P12SS6	2
A16H1208SS6LP	83600	406	305	203	Stainless Steel 316L	1.98	330 × 229	A16P12	Small	A16P12G	A16P12SS6	2
A20H1608SSLP	29020	508	406	203	Stainless Steel 304	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H1608SS6LP	29170	508	406	203	Stainless Steel 316L	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H2008SSLP	11088	508	508	203	Stainless Steel 304	1.98	432 × 432	A20P20	Small	A20P20G	A20P20SS6	2
A20H2008SS6LP	83610	508	508	203	Stainless Steel 316L	1.98	432 × 432	A20P20	Small	A20P20G	A20P20SS6	2
A20H2408SSLP	29060	508	610	203	Stainless Steel 304	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	2
A20H2408SS6LP	83620	508	610	203	Stainless Steel 316L	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	2
A24H1608SSLP	24030	610	406	203	Stainless Steel 304	1.98	533 × 330	A24P16	Small	A24P16G	A24P16SS6	3
A24H1608SS6LP	83630	610	406	203	Stainless Steel 316L	1.98	533 × 330	A24P16	Small	A24P16G	A24P16SS6	3
A24H2008SSLP	29030	610	508	203	Stainless Steel 304	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A24H2008SS6LP	29100	610	508	203	Stainless Steel 316L	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A24H2408SSLP	24100	610	610	203	Stainless Steel 304	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A24H2408SS6LP	29110	610	610	203	Stainless Steel 316L	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A24H3008SSLP	23870	610	762	203	Stainless Steel 304	1.98	686 × 533	A30P24	Small	A30P24G	A30P24SS6	7
A24H3008SS6LP	83640	610	762	203	Stainless Steel 316L	1.98	686 × 533	A30P24	Small	A30P24G	A30P24SS6	7
A30H2008SSLP	23880	762	508	203	Stainless Steel 304	1.98	686 × 432	A30P20	Small	A30P20G	A30P20SS6	3
A30H2008SS6LP	83650	762	508	203	Stainless Steel 316L	1.98	686 × 432	A30P20	Small	A30P20G	A30P20SS6	3
A30H2408SSLP	24110	762	610	203	Stainless Steel 304	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A30H2408SS6LP	29120	762	610	203	Stainless Steel 316L	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A30H3008SSLP	24040	762	762	203	Stainless Steel 304	1.98	686 × 686	A30P30	Large	A30P30G	A30P30SS6	7
A30H3008SS6LP	83660	762	762	203	Stainless Steel 316L	1.98	686 × 686	A30P30	Large	A30P30G	A30P30SS6	7
A36H2408SSLP	24120	914	610	203	Stainless Steel 304	1.98	838 × 533	A36P24	Large	A36P24G	A36P24SS6	3
A36H2408SS6LP	83670	914	610	203	Stainless Steel 316L	1.98	838 × 533	A36P24	Large	A36P24G	A36P24SS6	3
A36H3008SSLP	24130	914	762	203	Stainless Steel 304	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A36H3008SS6LP	29130	914	762	203	Stainless Steel 316L	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7

Catalog Number	Article Number	Height (mm)	Width (mm)	Depth (mm)	Material	Thickness (mm)	Panel Size (mm)	Steel Panel	Data Pocket	Conductive Steel Panel	Stainless Steel Panel	Clamp Quantity
A42H3608SSLP	23890	1067	914	203	Stainless Steel 304	1.98	991 × 838	A42P36	Large	A42P36G	A42P36SS6	8
A42H3608SS6LP	83680	1067	914	203	Stainless Steel 316L	1.98	991 × 838	A42P36	Large	A42P36G	A42P36SS6	8
A48H3608SSLP	24140	1219	914	203	Stainless Steel 304	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A48H3608SS6LP	83690	1219	914	203	Stainless Steel 316L	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A20H1610SSLP	24150	508	406	254	Stainless Steel 304	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A20H1610SS6LP	83700	508	406	254	Stainless Steel 316L	1.98	432 × 330	A20P16	Small	A20P16G	A20P16SS6	2
A24H2010SSLP	24160	610	508	254	Stainless Steel 304	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A24H2010SS6LP	83710	610	508	254	Stainless Steel 316L	1.98	533 × 432	A24P20	Small	A24P20G	A24P20SS6	3
A30H2410SSLP	11092	762	610	254	Stainless Steel 304	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A30H2410SS6LP	83720	762	610	254	Stainless Steel 316L	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A36H2410SSLP	24170	914	610	254	Stainless Steel 304	1.98	838 × 533	A36P24	Large	A36P24G	A36P24SS6	3
A36H2410SS6LP	83730	914	610	254	Stainless Steel 316L	1.98	838 × 533	A36P24	Large	A36P24G	A36P24SS6	3
A36H3010SSLP	24180	914	762	254	Stainless Steel 304	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A36H3010SS6LP	83740	914	762	254	Stainless Steel 316L	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A42H3010SSLP	24190	1067	762	254	Stainless Steel 304	1.98	991 × 686	A42P30	Large	A42P30G	A42P30SS6	8
A42H3010SS6LP	83750	1067	762	254	Stainless Steel 316L	1.98	991 × 686	A42P30	Large	A42P30G	A42P30SS6	8
A48H3610SSLP	11093	1219	914	254	Stainless Steel 304	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A48H3610SS6LP	83760	1219	914	254	Stainless Steel 316L	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A24H2412SSLP	24200	610	610	305	Stainless Steel 304	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A24H2412SS6LP	83770	610	610	305	Stainless Steel 316L	1.98	533 × 533	A24P24	Small	A24P24G	A24P24SS6	3
A30H2412SSLP	24210	762	610	305	Stainless Steel 304	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A30H2412SS6LP	29140	762	610	305	Stainless Steel 316L	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A36H3012SSLP	24220	914	762	305	Stainless Steel 304	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A36H3012SS6LP	29150	914	762	305	Stainless Steel 316L	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A36H3612SSLP	29070	914	914	305	Stainless Steel 304	1.98	838 × 838	A36P36	Large	A36P36G	A36P36SS6	7
A36H3612SS6LP	83790	914	914	305	Stainless Steel 316L	1.98	838 × 838	A36P36	Large	A36P36G	A36P36SS6	7
A48H3612SSLP	23900	1219	914	305	Stainless Steel 304	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A48H3612SS6LP	83800	1219	914	305	Stainless Steel 316L	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A60H3612SSLP	24230	1524	914	305	Stainless Steel 304	1.98	1448 × 838	A60P36	Large	A60P36G	A60P36SS6	9
A60H3612SS6LP	83810	1524	914	305	Stainless Steel 316L	1.98	1448 × 838	A60P36	Large	A60P36G	A60P36SS6	9
A30H2416SSLP	29040	762	610	406	Stainless Steel 304	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A30H2416SS6LP	83820	762	610	406	Stainless Steel 316L	1.98	686 × 533	A30P24	Large	A30P24G	A30P24SS6	3
A36H3016SSLP	23910	914	762	406	Stainless Steel 304	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A36H3016SS6LP	83830	914	762	406	Stainless Steel 316L	1.98	838 × 686	A36P30	Large	A36P30G	A36P30SS6	7
A48H3616SSLP	23920	1219	914	406	Stainless Steel 304	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A48H3616SS6LP	29160	1219	914	406	Stainless Steel 316L	1.98	1143 × 838	A48P36	Large	A48P36G	A48P36SS6	8
A60H3616SSLP	11094	1524	914	406	Stainless Steel 304	1.98	1448 × 838	A60P36	Large	A60P36G	A60P36SS6	9
A60H3616SS6LP	83780	1524	914	406	Stainless Steel 316L	1.98	1448 × 838	A60P36	Large	A60P36G	A60P36SS6	9

Purchase panels separately. Optional composite and aluminum panels are available for most sizes.

CONTINUOUS HINGE WITH CLAMPS, TYPE 4X

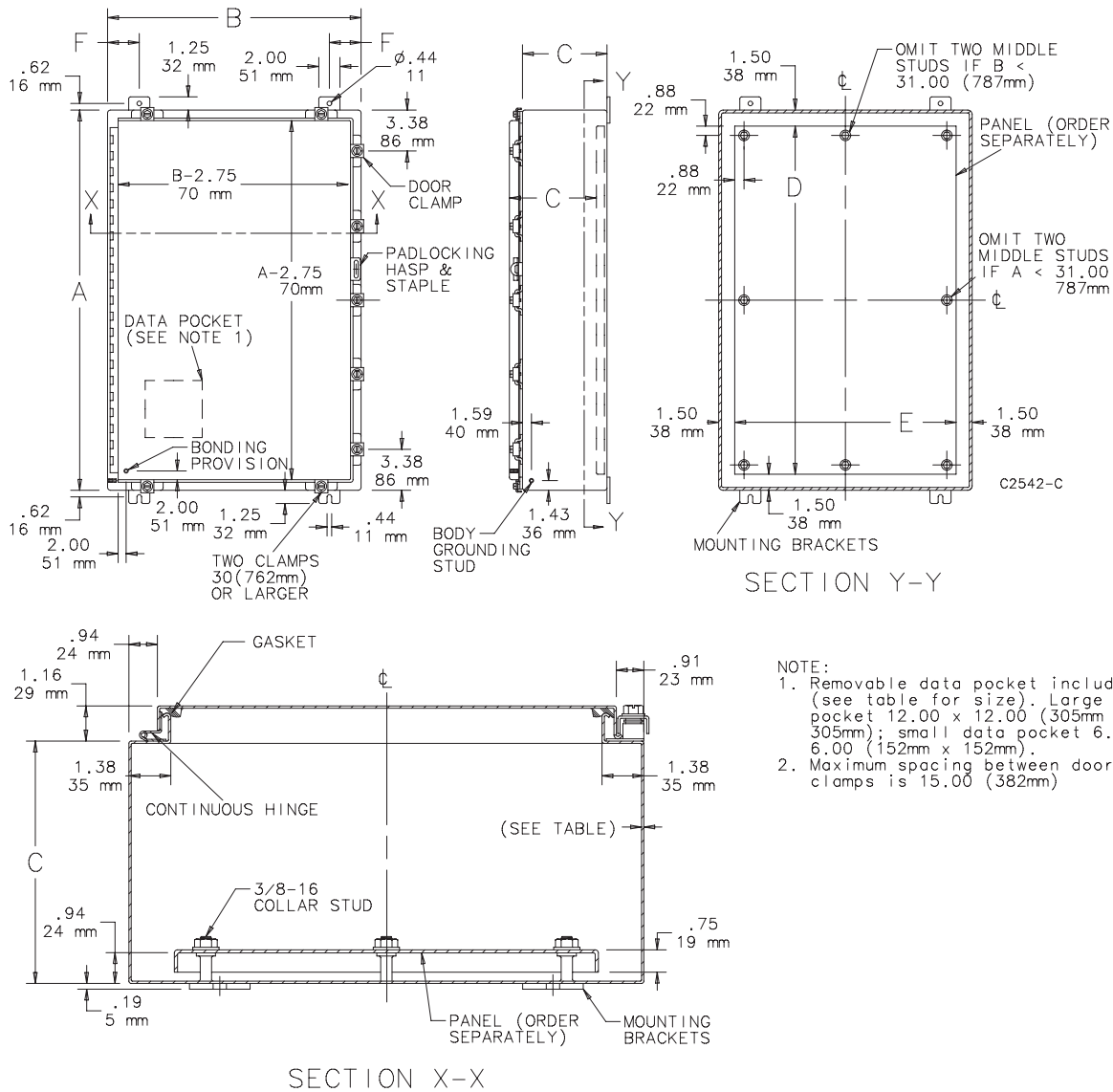

POPULAR COOLING PRODUCTS

Enclosure Depth (C Dimension)	Thermoelectric Controller
6 in. (152 mm)	TE090624011
8 in. (203 mm)	TE162024011
10 in. (254 mm)	TE162024011
12 in. (305 mm)	TE162024011
16 in. (406 mm)	TE162024011

*Important: Visit tools.hoffmanonline.com/attachments to access our Cooling Selection Tool to determine the appropriate cooling solution for your application.

POPULAR ACCESSORIES

Enclosure Width (B Dimension)	Lights	Hole Seals	Window Kits
12 in. (305 mm)	LEDPUCK	AS050SS	APWK53NFSS
16 in. (406 mm)	LEDA2M35	AS050SS	APWK53NFSS
20 in. (508 mm)	LED24V15	AS050SS	APWK53NFSS
24 in. (610 mm)	LED24V15	AS050SS	APWK53NFSS
30 in. (762 mm)	LED24V15	AS050SS	APWK53NFSS
36 in. (914 mm)	LED24V15	AS050SS	APWK53NFSS



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE