


nVent CADDY Box Mounting Plate with Far Side Support on Stud Assembly

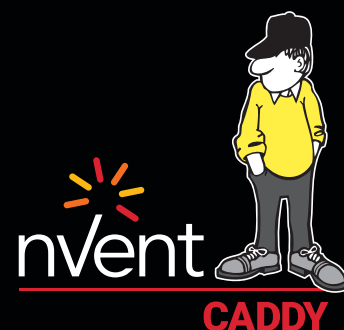

CONNECT AND PROTECT

The nVent CADDY Box Mounting Plate with Far Side Support on Stud Assembly line increases overall productivity, savings, and job site safety. For ultimate flexibility, the assemblies are configured with the most common box and mud ring combinations. The line is also offered in both standard and open back boxes as well as in single and double gang fixed or adjustable depth mud rings. When paired with the nVent CADDY Open Back Box, the assembly is ideal for prefab installations where devices, fittings, and cables are installed to quickly and easily complete make-up wiring connections, without the need to drop or work through the mud ring.



FEATURES

- Snap-on design feature makes it easy to snap onto Heavy Duty Telescoping Box Brackets (TB1624HD and TB914HD) for between stud applications
- Snap-on installation to Heavy Duty Telescoping Bracket allows for easy positioning along bracket
- Can also be mounted directly to metal or wood studs
- Innovative far side support allows bracket to be installed on virtually any stud depth and up to 3" wide studs
- Extruded holes allow mounting of mud rings for both power and data applications
- Key holes provide ease of installation and positive location when mounting boxes
- Accepts vertically or horizontally mounted single and double gang adjustable mud rings
- Box Lock tab secures box to bracket during assembly and allows mud ring to be removed following installation on the stud, providing easy frontal access to the inside of the box
- Box Lock feature is ideal for prefab assemblies

Finish: Pregalvanized
Material: Steel

Catalog Number	Knockout Sizes	Box Type	Gang	Mud Ring Type	Box Size	Box Depth	Box Volume	Ground Wire Included	Drywall Thickness
PK4D	(4) ½", ¾", (8) ½"	Closed	—	—	4"	2.12"	30.3 in³	Yes	—
PK4DM1	(4) ½", ¾", (8) ½"	Closed	1	Raised	4"	2.12"	30.3 in³	Yes	⅝"
PK4DM2	(4) ½", ¾", (8) ½"	Closed	2	Raised	4"	2.12"	30.3 in³	Yes	⅝"
PK4DV1	(4) ½", ¾", (8) ½"	Closed	1	Adjustable	4"	2.12"	30.3 in³	Yes	⅝" – 1½"
PK4DV2	(4) ½", ¾", (8) ½"	Closed	2	Adjustable	4"	2.12"	30.3 in³	Yes	⅝" – 1½"
PKD1	(4) 1", (4) 1¼"	Closed	—	—	4 ¹¹ / ₁₆ "	2.12"	42 in³	No	—
PKD1M5	(4) 1", (4) 1¼"	Closed	1	Raised	4 ¹¹ / ₁₆ "	2.12"	42 in³	No	⅝"
PKP1	(12) ½", ¾"	Closed	—	—	4 ¹¹ / ₁₆ "	2.12"	42 in³	Yes	—
PKP1M5	(12) ½", ¾"	Closed	1	Raised	4 ¹¹ / ₁₆ "	2.12"	42 in³	Yes	⅝"
PKP1M6	(12) ½", ¾"	Closed	2	Raised	4 ¹¹ / ₁₆ "	2.12"	42 in³	Yes	⅝"
PKX4	(4) ½", ¾", (7) ½"	Open	—	—	4"	2.12"	32.8 in³	Yes	—
PKX4M1	(4) ½", ¾", (7) ½"	Open	1	Raised	4"	2.12"	32.8 in³	Yes	⅝"
PKX4M2	(4) ½", ¾", (7) ½"	Open	2	Raised	4"	2.12"	32.8 in³	Yes	⅝"
PKX4V1	(4) ½", ¾", (7) ½"	Open	1	Adjustable	4"	2.12"	32.8 in³	Yes	⅝" – 1½"
PKX4V2	(4) ½", ¾", (7) ½"	Open	2	Adjustable	4"	2.12"	32.8 in³	Yes	⅝" – 1½"



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER