

nVent CADDY Flared Couplers



The nVent CADDY Flared Coupler series is designed to reduce the number of steps required for installing conduit racks. The integrated flare helps align each piece of conduit to easily join and install prefabricated conduit racks. This product line includes two options for working with multiple variations of conduit hanging systems:

- nVent CADDY Flared Slip Couplers
- nVent CADDY Flared Traditional Couplers


NVENT CADDY FLARED SLIP COUPLER



Features

- Designed for EMT conduit
- Fast and simple installation
- Center viewport assists in conduit placement

Part Number	Length L	Width W	Height H	Depth D	Certifications
SC0050	1.795"	1.043"	1.499"	0.729"	–
SC0075	2.185"	1.3"	1.756"	0.945"	UL, cUL
SC0100	2.72"	1.625"	2.075"	1.185"	UL, cUL
SC0125	3.325"	1.93"	2.39"	1.535"	UL, cUL
SC0150	3.872"	2.388"	2.848"	1.772"	UL, cUL
SC0200	4.187"	2.85"	3.31"	2.234"	UL, cUL
SC0250	4.828"	3.854"	4.385"	2.92"	UL, cUL
SC0300	4.999"	4.41"	4.941"	3.552"	UL, cUL
SC0350	5.479"	5.242"	5.773"	4.057"	UL, cUL
SC0400	5.675"	5.748"	6.279"	4.563"	UL, cUL

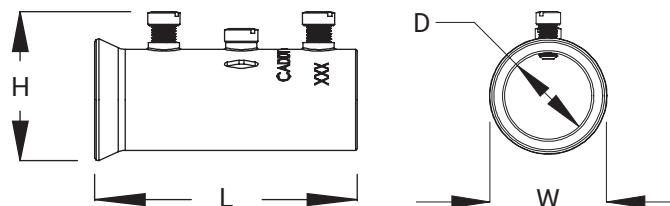




Features

- Designed for EMT conduit
- Fast and simple installation
- Center view slit in couplers center assists in conduit placement
- Integrated flare feature is ideal for prefabrication

Part Number	Length L	Width W	Height H	Depth D	Certifications
FC0050	1.795"	1.043"	1.499"	0.729"	–
FC0075	2.185"	1.3"	1.756"	0.945"	UL, cUL
FC0100	2.72"	1.625"	2.075"	1.185"	UL, cUL
FC0125	3.325"	1.93"	2.39"	1.535"	UL, cUL
FC0150	3.872"	2.388"	2.848"	1.772"	UL, cUL
FC0200	4.187"	2.85"	3.31"	2.234"	UL, cUL
FC0250	4.828"	3.854"	4.385"	2.92"	UL, cUL
FC0300	4.999"	4.41"	4.941"	3.552"	UL, cUL
FC0350	5.479"	5.242"	5.773"	4.057"	UL, cUL
FC0400	5.675"	5.748"	6.279"	4.563"	UL, cUL

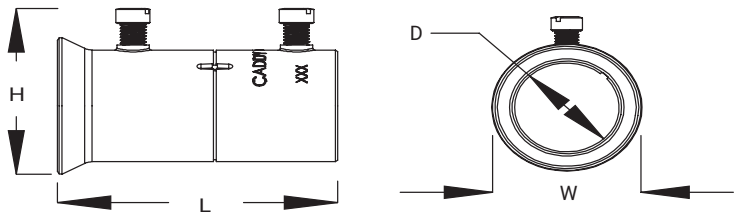

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE