


PermaGround Water and Gas Pipe Ground Clamp

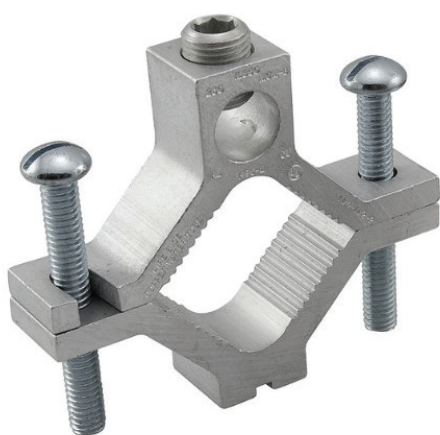


nVent ERICO PermaGround Water and Gas Pipe Ground Clamp is engineered of high-strength 6061-T6 aluminum alloy and are used for connecting copper or aluminum conductors to copper water pipe, galvanized pipe or steel conduit. The conductor and pipe range taking capabilities make this connector ideal for installations requiring long ground wire runs.

FEATURES

- Used for connecting copper water pipe, galvanized pipe or steel conduit
- Suitable for use with copper or aluminum conductors



Part Number	Material	For Outdoor Use	Pipe Size, Nominal Ø	Hex Width W	Conductor Size	Certifications
AGC-1	Aluminum	Yes	0.5 - 1	–	#14 Stranded - 1/0 Stranded	–
AGC-2	Aluminum	Yes	1.25 - 2	–	#6 Solid - 250 kcmil Stranded	–
AGC-4	Aluminum	Yes	2.5 - 4	–	#6 Solid - 250 kcmil Stranded	–
SGC-1/0	Aluminum	No	0.5 - 1	–	#14 Stranded - 1/0 Stranded	–
CWP1J	Silicon Bronze	No	½" - 1"	1.00" - 1¼"	#10 Solid - #2 Solid, 6 mm² Solid - 25 mm² Stranded	CSA, cUL, UL
CWP2J	Silicon Bronze	No	1¼" - 2"	1½" - 2⅝"	#10 Solid - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded	CSA, cUL, UL
CWP3J	Silicon Bronze	No	2½" - 4"	2½" - 3⅝"	#10 Solid - #4 Stranded, 6 mm² Stranded - 16 mm² Stranded	cUL, UL
CWP1JSH	Silicon Bronze	Yes	½" - 1"	1.00" - 1¼"	#10 Solid - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded	cUL, UL
CWP2JSH	Silicon Bronze	Yes	1¼" - 2"	1½" - 2⅝"	#10 Solid - #2 Stranded, 6 mm² Solid - 25 mm² Stranded	cUL, UL
CWP3JSH	Silicon Bronze	Yes	2½" - 4"	2½" - 3⅝"	#10 Solid - #4 Stranded, 6 mm² Stranded - 16 mm² Stranded	cUL, UL

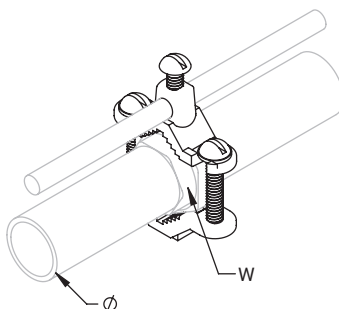



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE