

PermaGround Intersystem Ground Tap



nVent ERICO PermaGround Lay-In Intersystem Ground Tap allows for fast and simple installation on a ground conductor below the meter. The lay-in style eliminates the need to cut or splice into existing conductors, and with no mounting required. The tap is dual-rated for use with both copper and aluminum conductors.


FEATURES

- Lay in style, eliminates the need to cut or splice into existing conductor
- No mounting required, allows fast simple installation on ground conductor below meter
- Dual-rated for use with copper and aluminum conductors

Material: Aluminum



Part Number	Conductor Material	Main/Run Conductor Range	Direct Burial	Height H	Length L	Width W	Unit Weight
GBT-1/0	Copper, Aluminum	1/0 - 8 AWG	No	1.16"	2.25"	1.125"	0.217 lb
GBT-1/0-M	Copper, Aluminum	1/0 - 8 AWG	No	1.16"	2.25"	1.75"	0.24 lb
GBT-1/0-M-W/C	Copper, Aluminum	1/0 - 8 AWG	No	2.244"	3.922"	2.925"	0.326 lb
GBT-250	Copper, Aluminum	250 kcmil - 8 AWG	No	1.587"	2.25"	1.375"	0.405 lb

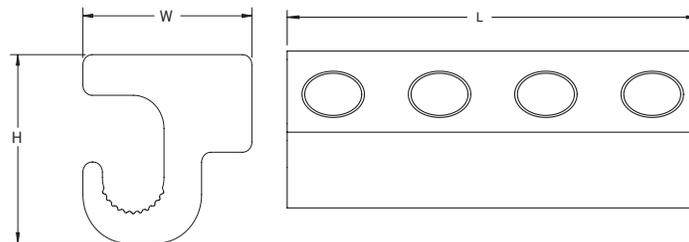

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE