

PermaGround Surface Bonding Jumper




nVent ERICO PermaGround Surface Bonding Jumper is a conductor used to ensure electrical continuity and a low-impedance path for fault currents between metal parts that need to be electrically connected.



Material: Copper

Part Number	Conductor Type	Conductor Material	Connector Finish	Wire Size	Height H	Length L	Width W	Unit Weight
SBJ-38-6	Stranded	Copper	Tinned	#6	10.134"	169.418"	17.018"	0.649 lb
SBJ-38-9	Stranded	Copper	Tinned	#6	10.134"	245.618"	17.018"	0.879 lb
SBJ-38-18	Stranded	Copper	Tinned	#6	10.134"	474.218"	17.018"	1.443 lb
SBJ-38-712	Stranded	Copper	Tinned	#6	10.134"	207.518"	17.018"	0.605 lb
SBJ-14-6	Stranded	Copper	Tinned	#6	10.134"	169.418"	17.018"	0.7 lb
SBJ-14-12	Stranded	Copper	Tinned	#6	10.134"	321.818"	17.018"	0.19 lb
SBJ-14-24	Stranded	Copper	Tinned	#6	10.134"	626.618"	17.018"	1.921 lb
SBJ-14-32	Stranded	Copper	Tinned	#6	10.134"	829.818"	17.018"	2.559 lb
SBJ-14-36	Stranded	Copper	Tinned	#6	10.134"	931.418"	17.018"	2.878 lb
SBJ-14-712	Stranded	Copper	Tinned	#6	10.134"	207.518"	17.018"	0.605 lb
SBJ-14-1012	Stranded	Copper	Tinned	#6	10.134"	283.718"	17.018"	0.17 lb
SBJ-516-6	Stranded	Copper	Tinned	#6	10.134"	169.418"	17.018"	0.68 lb
SBJ-516-9	Stranded	Copper	Tinned	#6	10.134"	245.618"	17.018"	0.89 lb
SBJ-516-32	Stranded	Copper	Tinned	#6	10.134"	829.818"	17.018"	0.48 lb
SBJ-516-40	Stranded	Copper	Tinned	#6	10.134"	1033.018"	17.018"	0.6 lb
SBJ-516-72	Stranded	Copper	Tinned	#6	10.134"	1845.818"	17.018"	0.15 lb
SBJ-516-712	Stranded	Copper	Tinned	#6	10.134"	207.518"	17.018"	0.61 lb
SBJ-516-1012	Stranded	Copper	Tinned	#6	10.134"	283.718"	17.018"	0.17 lb

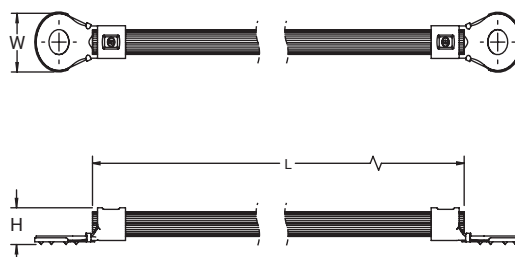



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE