

nVent CADDY RS Retrofit Retainer Strap



The nVent CADDY RS Retrofit Retainer Strap is designed to assist in the securement of beam clamps and other flanges to metal structures. Due to the post-installation function, the RS Retrofit Retainer Strap can be added to pre-existing hanging systems without dismantling any clamps or threaded rods already in place. With a teardrop-shaped opening to lock onto the rod, contractors can be confident that components will not shift during installation and will retain their integrity even in the case of a seismic event.

FEATURES:


- Ideal for both new and existing applications
- Designed for use with the nVent CADDY Beam Clamps and Accessories
- Can be secured to either the set screw or threaded rod
- Large teardrop-shaped opening is compatible with multiple threaded rod diameters, significantly reducing inventory
- Provides a secure attachment in seismic zones and complies with NFPA requirements

Material: Steel
Finish: Pregalvanized



Part Number	Length L	Width W	Thickness T	Rod Size RS	Hole Size HS	Retainer Male End A
RS06	6 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS08	8 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS10	10 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS12	12 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS14	14 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS16	16 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"
RS18	18 1/2"	1 3/4"	16 GA	3/8", 1/2"	1 1/8"	3 1/4"

Add 2" to width of flange to determine minimum length strap required.

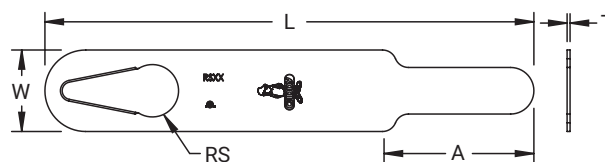

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

