 


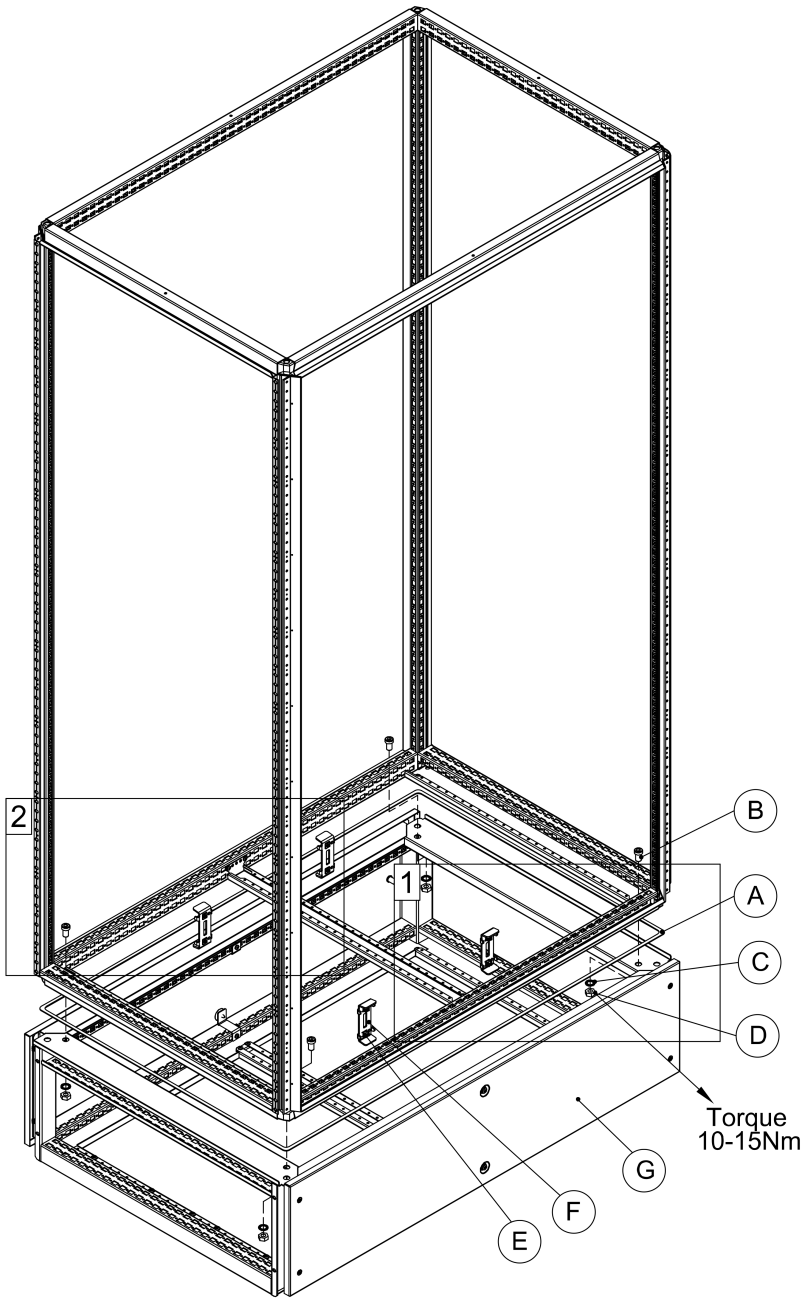


PCU



Ref.	Pic.	
A	 4.5x8	1
B	 M12x20	4
C	 M12	4
D	 M12	4
E	 CCI06	4/8
F	 CCI06	2/4
G	 CBP	1

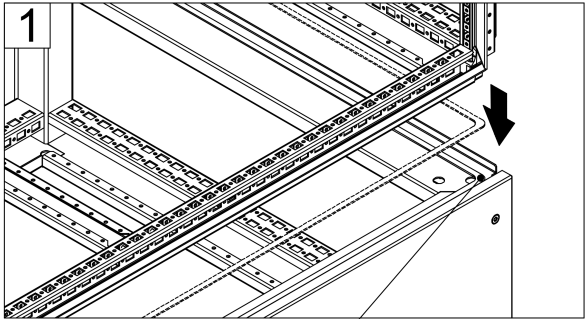


!Note
ALTERNATIVE FIXATION WITH CNT05 (*to be ordered separately)
IP55 protection can be achieved by sealing the bottom opening using the BG01 gasket and bottom plates (CBP)

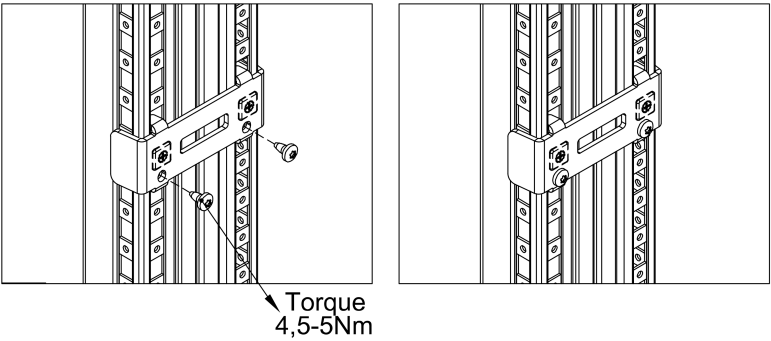




 
! The adhesive gasket "A" must be fixed outside the frame corner holes

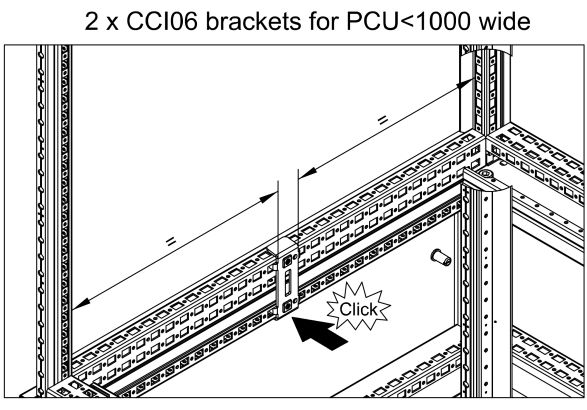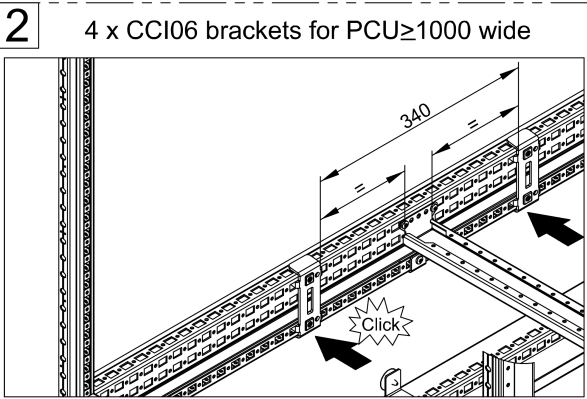




Baying

Ref.	Pic.	
A	 4.5x8	1
B		2

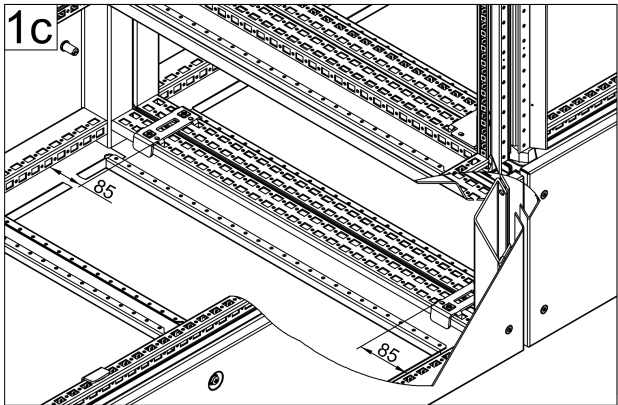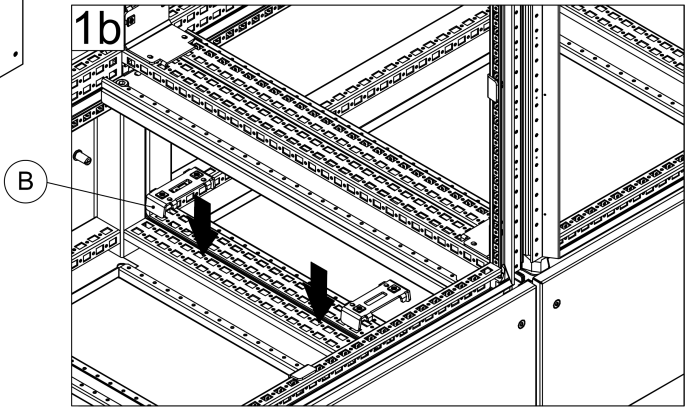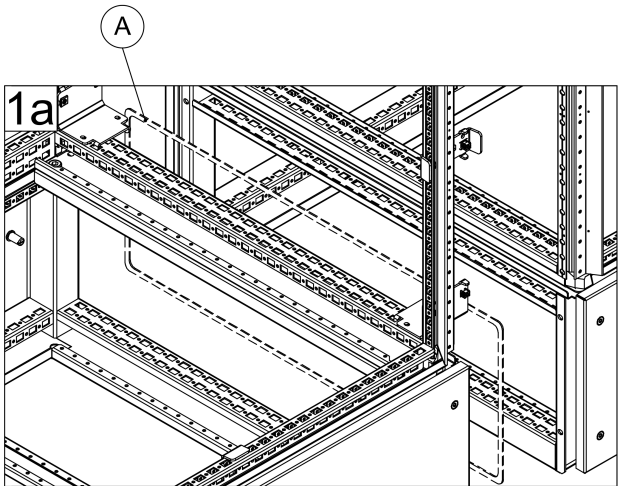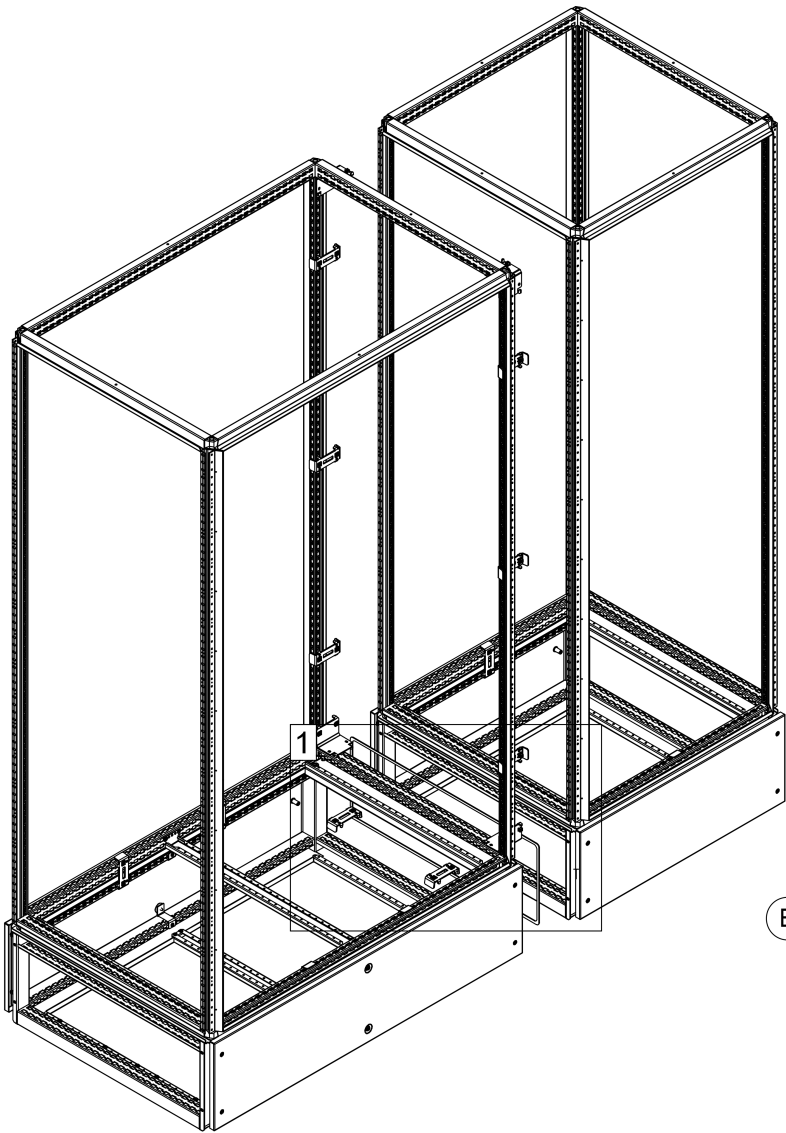

!Note
CCI06 bracket for baying must be ordered separately
ALTERNATIVE FIXATION WITH CNT05 (*to be ordered separately)

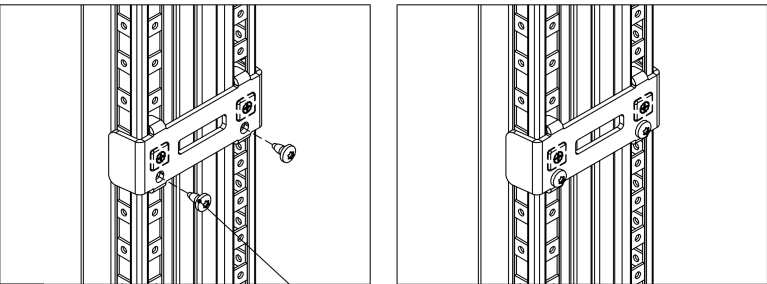

Torque
4,5-5Nm