
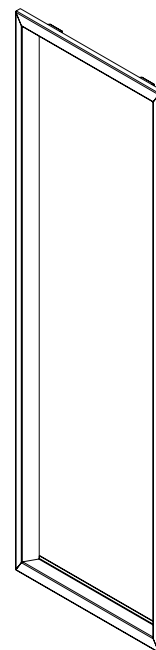


## DRESS FRAME

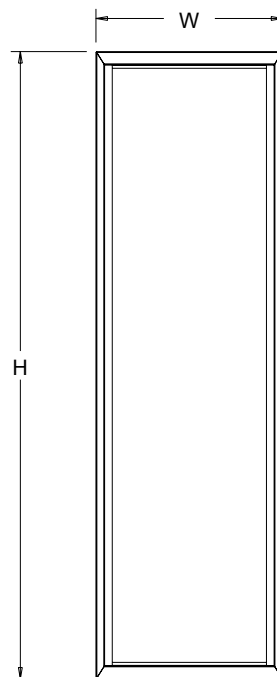

89129480

### APPLICATION

A PROLINE G2 Dress Frame provides a decorative trim when a front door or cover is not used. It is frequently used for open rack applications.

### SPECIFICATIONS

- Provides a clean, finished aesthetic for open rack applications
- Snap-in design for easy, tool-free installation

### FINISH

- Polyester powder paint; RAL 7035 textured light gray standard
- Custom colors available

### ACCESSORIES

- 19-Inch Rack Angles
- Rack Panels
- Rack-Mount Fixed Shelf
- Rack Mount Pull-Out Shelf
- Guides
- Slides
- Rack-Angle Mounted Drawer
- Writing Surface

### BULLETIN: P40

#### Standard Product

| Catalog Number | H (mm) | H (in.) | W (mm) | W (in.) | Fits Frame Height x Width mm |
|----------------|--------|---------|--------|---------|------------------------------|
| P2DF126        | 1192   | 46.9    | 593    | 23.4    | 1200x600                     |
| P2DF146        | 1392   | 54.8    | 593    | 23.4    | 1400x600                     |
| P2DF148        | 1392   | 54.8    | 793    | 31.2    | 1400x800                     |
| P2DF166        | 1592   | 62.7    | 593    | 23.4    | 1600x600                     |
| P2DF168        | 1592   | 62.7    | 793    | 31.2    | 1600x800                     |
| P2DF186        | 1792   | 70.6    | 593    | 23.4    | 1800x600                     |
| P2DF188        | 1792   | 70.6    | 793    | 31.2    | 1800x800                     |
| P2DF206        | 1992   | 78.4    | 593    | 23.4    | 2000x600                     |
| P2DF208        | 1992   | 78.4    | 793    | 31.2    | 2000x800                     |
| P2DF226        | 2192   | 86.3    | 593    | 23.4    | 2200x600                     |
| P2DF228        | 2192   | 86.3    | 793    | 31.2    | 2200x800                     |

| Model      | Component | Type                                                                                                                                                                                          | Height                                                                                                                         | Width                    | Specialty                              | Catalog Number |
|------------|-----------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------|--------------------------|----------------------------------------|----------------|
| P2         | D         | F                                                                                                                                                                                             | 20                                                                                                                             | 8                        | Blank                                  | = P2DF208      |
| PROLINE G2 | Door      | Blank = single door<br>O = double door<br>W = window door<br>A = side door adapter<br>DR = disconnect right<br>DL = disconnect left<br>DR2 = disconnect right large cutout<br>F = dress frame | mm<br>22 = 2200<br>20 = 2000<br>18 = 1800<br>16 = 1600<br>14 = 1400<br>12 = 1200<br>10 = 1000<br>8 = 800<br>6 = 600<br>4 = 400 | mm<br>8 = 800<br>6 = 600 | Blank = standard<br>HF = EMC protected |                |

NOTE: Not every combination is available as a standard product.

Notes