


4-poligt distributionsblock, 40 A, 2 inkommande & 11 utgående kablar

Data Solutions

KATALOGNUMMER

TD-40A

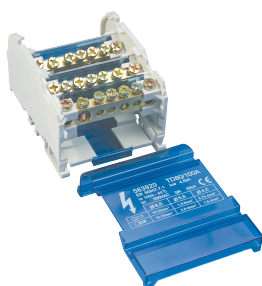

CERTIFIERINGAR



DESIGN

Uppfyller RoHS

Halogenfri

Minimum space for maximum power

Protection cover and insulating screens are transparent

Insulating screen between each row

Easy and safe connections

Easily clips onto DIN rail or mounts to panel with screws

Solid bars provide reliability

Wiring with or without terminal

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

PRODUKTATTRIBUT


Artikelnummer: 563740
Material: Termoplast; Mässing
Max. strömstyrka, IEC: 40A
Kortfristig resistansström (Icw) 1s.: 4.5kA
Kortslutningsström (IPK): 22kA
Max. arbetsspänning, IEC (UI): 500
Antal anslutningar på ledningssidan: 2
Line Side kompakt tvinnad trådstorlek: 6–16 mm²
Kabelstorlek på ledningssidan - hylsa: 4 – 10mm²
Antal anslutningar på lastsidan: 11
Lastsidan kompakt tvinnad trådstorlek: (11) 1,5–4 mm²
Kabelstorlek på lastsidan - hylsa: (11) 0,75–4 mm²
Djup (D): 50mm
Höjd (H): 90mm
Bredd (W): 100mm
Enhetens vikt: 0.33kg
Brandklass: UL® 94V-0
Överensstämmer med.: IEC® 60947-7-1

YTTERLIGARE PRODUKTINFORMATION

Line side and load side number of connections are per pole.

Design Guideline for Distribution Blocks, Power Blocks and Power Terminals										
Derating according to Ambient* Temperature (°C) to maintain working temperature of 85°C										
Ambient Temperature (°C)	30°	35°	40°	45°	50°	55°	60°	65°	70°	75°
Derating Coefficient (d)	1	1	1	0.94	0.88	0.82	0.75	0.67	0.58	0.47
*environment around the terminal blocks inside the enclosure										

DIAGRAMS

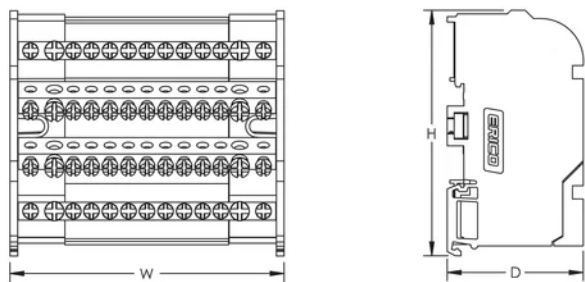

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE