

nVent ERIFLEX Flexbus HCBC Plate with PE Connection

Data Solutions



CERTIFIERINGAR



DESIGN

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

HCBC Plate with PE connection allows conductor to be added to interconnect neutral and ground/earth

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPECIFIKATIONER

Material: Koppar

Yta: Förtentat

Table 1/2

Katalognummer	Artikelnummer	A	B	C	D	E
FLEXPLATE100 PE	508183	115mm	100mm	45mm	51mm	70mm
FLEXPLATE50P E	508182	65mm	100mm	45mm	41mm	70mm


Table 2/2

Katalognummer	Artikelnummer	Hålstorlek 1 (HS1)	Hålstorlek 2 (HS2)	Tjocklek (T)	Ledarstorlek	Enhetsvikt
FLEXPLATE100 PE	508183	12.5mm	18.5mm	5mm	960 mm ² , 1280 mm ² , 1810 mm ²	0.71kg
FLEXPLATE50P E	508182	10.5mm	14.5mm	5mm	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.49kg

YTTERLIGARE PRODUKTINFORMATION

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

DIAGRAMS

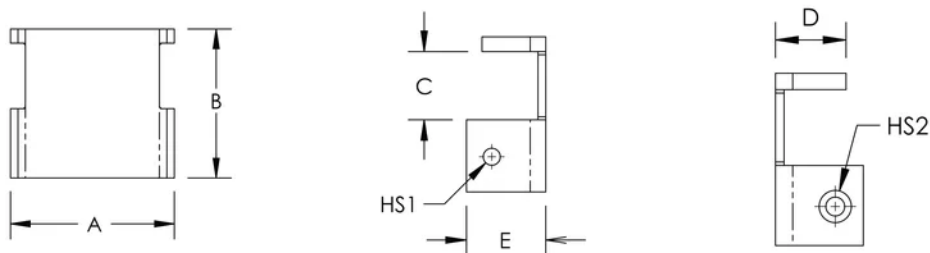

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE