


TRS Four Pole Distribution Block, 160 A

Data Solutions

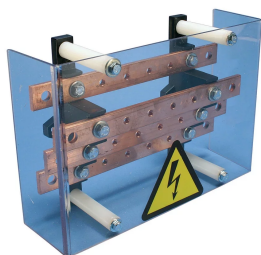

CERTIFIERINGAR



DESIGN

Easily fixes onto asymmetric DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER


Katalognummer	TRS-160A
Artikelnummer	563160
Material	Koppar Glasfiberförstärkt polyamid Plexiglas

Katalognummer	TRS-160A
Max. arbetsspänning, IEC (Ui)	630
Maximal kortslutningsström (Ipk)	34kA
Kortsiktig hållström (Icw) 1s	13.2kA
Antal anslutningar på ledningssida	2
Antal anslutningar på belastningssida	4
Hålstorlek (HS)	8mm
Trådstorlek (TS)	M6
Djup (D)	68mm
Höjd (H)	150mm
Bredd (W)	230mm
Enhetsvikt	1.15kg
Brandklassning	UL® 94V-0
Uppfyller	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (glödtrådtest 960 °C)

YTTERLIGARE PRODUKTINFORMATION

Line side and load side number of connections are per pole.

DIAGRAMS

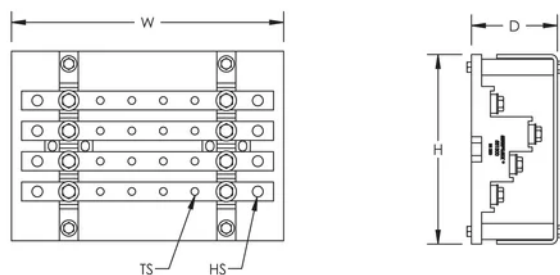

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE