

Vridbar adapter, hona-hane, Imperial gänga



CERTIFIERINGAR



DESIGN

Uppfångaren kan placeras vertikalt när basen finns på ett lutande tak

Hangänga inkluderar låsmutter för positionering

SPECIFIKATIONER


Table 1/2

Katalognummer	Artikelnummer	Material	Trådstorlek 1 (TS1)	Trådstorlek 2 (TS2)	Längd 1 (L1)	Längd 2 (L2)
LPC2813F3M	701974	Koppar	3/8-TUMS UNC	3/8-TUMS UNC	44.45 mm	69.85 mm

Table 2/2

Katalognummer	Artikelnummer	Enhetsvikt
LPC2813F3M	701974	0.23 kg

DIAGRAMS

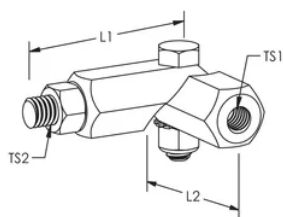

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE