

Stängselklämma, en ledare



The nVent ERICO Fence Clamp, One Conductor provides a secure and reliable grounding and bonding connection point for fence posts and gate structures, which is crucial for protecting equipment and personnel from electrical hazards. Engineered for durability and long-term performance, this specific clamp for a single conductor ensures system integrity in various industrial, commercial, and utility applications. Its versatile design and corrosion-resistant materials offer a dependable solution, simplifying installation while providing a lasting, maintenance-friendly connection that upholds the safety and resilience of your grounding infrastructure.

DESIGN

Stöldavskräckande utseende

Tillbehör i rostfritt stål ingår

Tennplätering minimerar risken för korrosion

Med klämmor kan ledningen läggas antingen parallellt eller i rät vinkel mot röret

Versatile design accepts the conductor placement either parallel or at right angles to the pipe or post

SPECIFIKATIONER

Slutför: Konserverad

Table 1/2

Katalognummer	Artikelnummer	Material	Stängselstolpens storlek, nominell	Stängselstolpens ytterdiameter, faktisk (Ø)	Ledarstorlek	nVent ERICO Cu-Bond ledare
FC074	198402	Bronze, Rostfritt stål 304 (en 1,4301)	1 1/2"	48 mm	2/0 Solid - 250 kcmil Stranded, 50 mm ² fåtrådig - 120 mm ² fåtrådig	
FC075	198403	Bronze, Rostfritt stål 304 (en 1,4301)	2"	60 mm	#4 Solid - 2/0 strängad, 16 mm ² Stranded - 70 mm ² Stranded	CBSC8

Katalognummer	Artikelnummer	Material	Stängselstolpe ns storlek, nominell	Stängselstolpe ytterdiameter, faktisk (Ø)	Ledarstorlek	nVent ERICO Cu-Bond ledare
FC076	198404	Bronze, Rostfritt stål 304 (en 1,4301)	2"	60 mm	2/0 Solid - 250 kcmil Stranded, 50 mm ² fåtrådig - 120 mm ² fåtrådig	CBSC10, CBSC13
FC082	198411	Bronze, Rostfritt stål 304 (en 1,4301)	3 1/2"	102 mm	2/0 Solid - 250 kcmil Stranded, 50 mm ² fåtrådig - 120 mm ² fåtrådig	
FC078	198406	Bronze, Rostfritt stål 304 (en 1,4301)	2 1/2"	73 mm	2/0 Solid - 250 kcmil Stranded, 16 mm ² fåtrådig - 120 mm ² fåtrådig	
FC079	198407	Bronze, Rostfritt stål 304 (en 1,4301)	3"	89 mm	#4 Solid - 2/0 strängad, 16 mm ² Stranded - 70 mm ² Stranded	


Table 2/2

Katalognummer	Artikelnummer	Överensstämmer med.
FC074	198402	
FC075	198403	IEC® 62561-1
FC076	198404	IEC® 62561-1
FC082	198411	
FC078	198406	
FC079	198407	

YTTERLIGARE PRODUKTINFORMATION

IEC-överensstämmelse gäller endast för angivna nVent ERICO Cu-Bond ledningar.

DIAGRAMS

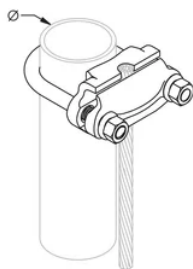

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE