

T-anslutning



DESIGN

För 90° ledningsanslutningar

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Material	Ledarstorlek	Djup (D)	Höjd (H)	Bredd (W)
CTR8CU	710030	Mässing	8 mm Solid, 10 mm, fast	21mm	46 mm	40 mm


Table 2/2

Katalognummer	Artikelnummer	nVent ERICO Cu-Bond-ledare	Enhetsvikt	Uppfyller
CTR8CU	710030	CBSC10	0.17 kg	IEC® 62561-1

YTTERLIGARE PRODUKTINFORMATION

IEC-överensstämmelse gäller endast för angivna nVent ERICO Cu-Bond ledningar.

DIAGRAMS

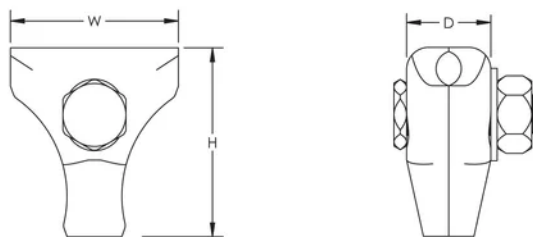

WARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE