


nVent ERIFLEX Flexbus HBC klämman

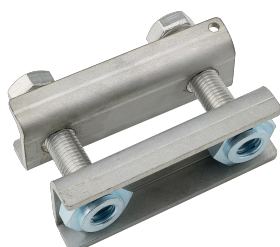

CERTIFIERINGAR



DESIGN

Monteras snabbt och enkelt

Uppfyller RoHS

Rigid design assures even contact pressure

Ideal for on-site modifications

Made with non-magnetic material stainless steel for high-current connections to prevent the formation of magnetic fields

Contains crimped self-locking nut for vibration resistance and easy installation

No drilling needed to fix the Flexbus Conductor on the transformer/power supply palm

Includes voltage detection connecting point

SPECIFIKATIONER

Material: Rostfritt stål 304 (en 1,4301)

Table 1/2

Katalognummer	Artikelnummer	A.	B.	C.	D.	Tjocklek (T)
---------------	---------------	----	----	----	----	--------------

FLEXCLAMP63	508190	63 mm	123 mm	20 mm	43 mm	4 mm
FLEXCLAMP80	508191	80 mm	140 mm	20 mm	43 mm	4 mm
FLEXCLAMP160	508194	160 mm	220 mm	20 mm	43 mm	4 mm
FLEXCLAMP100	508192	100 mm	160 mm	20 mm	43 mm	4 mm
FLEXCLAMP120	508193	120 mm	180 mm	20 mm	43 mm	4 mm

Table 2/2

Katalognummer	Artikelnummer	Hålstorlek (HS)	Vridmoment (TQ)	Enhetens vikt	Ledarebredd
FLEXCLAMP63	508190	5.5 mm	100 N·m	0.53 kg	30 - 63 mm
FLEXCLAMP80	508191	5.5 mm	100 N·m	0.84 kg	70 - 80 mm
FLEXCLAMP160	508194	5.5 mm	100 N·m	1.32 kg	130 - 160 mm
FLEXCLAMP100	508192	5.5 mm	100 N·m	0.92 kg	90 - 100 mm
FLEXCLAMP120	508193	5.5 mm	100 N·m	1 kg	110 - 120 mm


YTTERLIGARE PRODUKTINFORMATION

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

The minimum clearance distance is 14mm according to IEC 61439-1 with air pollution degree 3. If this distance cannot be respected, insulation material should be added between the metallic LV cover and the HCBC clamp. Flexbus IP2x Boots is also a solution.

If the Flexbus Conductors have a horizontal entry, an extender needs to be added between the power supply palm and HCBC Clamp and Plate.

DIAGRAMS

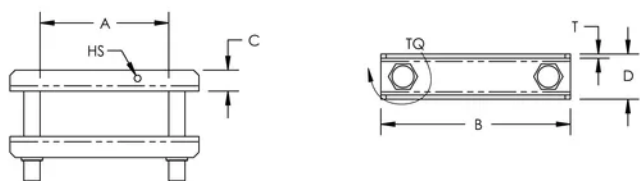

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE