


Kompakt samlingskena för strömdistribution, ECBS

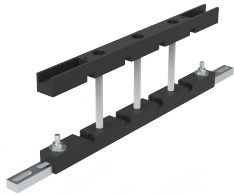

This busbar support, ECBS, is available for one or two bars up to 80 x 5 mm or one bar up to 80 x 10 mm. The support can be mounted both horizontally and vertically. It is available off the shelf and tested according to IEC 61439.

DESIGN

Beskrivning: Busbar support up to 1600A to be mounted horizontally or vertically. Mounts directly to the enclosure frame or with help of CLPF profiles. Available in single and double bar per phase for bar thickness 5 mm and only single bar per phase for bar thickness 10 mm, and width from 25 to 80 mm.

Arbetstemperatur: -40°C up to 130°C.

Material: Reinforced polyamide and steel. Halogen free.

Leverans: Busbar support with mounting material.

SPECIFIKATIONER

Table 1/1						
Katalognummer	E-nummer	Kapslingsmaterial	Produktfamilj	Material	Slutför	Färg
ECBS110TN	2505050	Mjukt stål	Fristående	Polyamid, Stål	Slät matt yta	Svart
ECBS205TN	2505051	Mjukt stål	Fristående	Plast, Mjukt stål	Jämn	

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE