


Genomföring liten 11-12mm

KATALOGNUMMER

CCFGS11

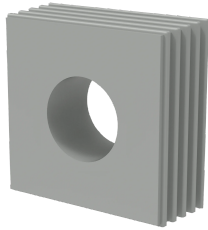

CCFGS cable glands are used with CCFI, CCFO and CCFR cable entry systems.

BRANSCHSTANDARDER

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

DESIGN

IP66 Modular Halogen-free and silicone free cable entry system, that provide versatility, variability and variety

Everything mounted from the outside of the enclosure

The frames, inlays and grommets can be combined in many ways - ensuring you many versatile configuration options

The frame does not need to be disassembled if requirements change or carrying out service work

No need to disassemble and reconnect connectors on cables so manufactures warranty is not voided

The conical shape of the grommets allows them to be easily pressed in, provides static strain relief in accordance with DIN EN 62444

For assembly, they are pressed from the inside out into the openings of the assembled inlays

The grommets are available in different sizes to match the diameter of the cable

The CCFGs is first placed around the cable and then inserted into the cable gland

Based on the wave-cut profile, there is no need to remove the connector on the assembled cabled

PRODUKTATTRIBUT

Höjd: 20.3mm

Bredd: 20.3mm

Djup: 17.7mm

Material: Plast

Slutför: Obehandlad

Färg: Grå

Drifttemperatur: -40 to 90°C

Vikt: 0.00589569160997732kg

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE