

T-Series Vertical Sleeve, 25 mm, #8, 25M, 127 mm

KATALOGNUMMER

RBT8101A



DESIGN

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice the same diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

PRODUKTATTRIBUT

Material: Stål

Yta: Standard

100 % inhemskt innehåll i USA: Ja

Glidlager: Standardlängd

Armeringsstorlek, metrisk: 25 mm

Armeringsstorlek, USA: #8

Armeringsstorlek, Kanada: 25M

Diameter 1 (Ø1): 48 mm

Diameter 2 (Ø2): 32 mm

Längd 1 (L1): 127 mm

Längd 2 (L2): 64 mm

Enhetsvikt: 0.98 kg


Utformad för att möta: AASHTO;ABNT NBR 8548:1984;ACI 318 typ 1 (125 % angivet utbyte);ACI 318 typ 2 (angiven draghållfasthet);ACI 349;ACI 359;AS3600

YTTERLIGARE PRODUKTINFORMATION

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

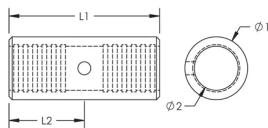

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE