

nVent LENTON Speed Sleeve Coupler



The nVent LENTON Speed Sleeve splice is a proven, quick and economical method of making compression-only splices in steel reinforced concrete projects. The system is designed to allow compressive loads to be transferred by aligning square cut reinforcing steel bar ends.

nVent LENTON Speed Sleeve is simple and easy to install. The small dimensions of the sleeve generally eliminate the need for additional concrete cover on the reinforcing steel because the sleeve is typically thinner than the column stirrups.

DESIGN

Bars can be individually secured

Fast, one-man installation

Requires only a lightweight ratchet wrench to install

Can be used on bundled bars

Self supporting; no tack welding is needed

Transition splices can be made using simple adaptor inserts

SPECIFIKATIONER

Yta: Elförzinkat

Material: Stål

Table 1/2

Katalognummer	Artikelnummer	Armeringsstorlek, metrisk	Armeringsstorlek, USA	Armeringsstorlek, Kanada	Längd (L)	Bredd (W)
RBW26810	145535	32 mm	#10		154mm	67 mm
RBW2687	145500	22 mm	#7		152mm	64 mm
RBW2686	145495	20 mm	#6	20M	154mm	54 mm
RBW2688	145510	25 mm	#8	25M	154mm	55 mm

Katalognummer	Artikelnummer	Armeringsstorlek, metrisk	Armeringsstorlek, USA	Armeringsstorlek, Kanada	Längd (L)	Bredd (W)
RBW2689	145520	28 mm	#9	30M	154mm	63 mm
RBW26811	145540	36 mm	#11	35M	203mm	67 mm
RBW26814		43 mm	#14	45M	280mm	77 mm
RBW26818	145560	57 mm	#18	55M	305mm	92 mm
RBW26840MM	145550	40 mm			280mm	74 mm
RBW26850	145555	50 mm			300mm	89 mm

Table 2/2

Katalognummer	Artikelnummer	Höjd (H)	Uttagsbredd (SW)	Antal bultar	Enhetsvikt
RBW26810	145535	47 mm	16mm	4	0.28 kg
RBW2687	145500	45 mm	16mm	3	0.53 kg
RBW2686	145495	37 mm	16mm	3	0.54 kg
RBW2688	145510	42 mm	16mm	3	0.59 kg
RBW2689	145520	45 mm	16mm	3	0.59 kg
RBW26811	145540	54 mm	16mm	4	0.91 kg
RBW26814		52 mm	16mm	4	1.38 kg
RBW26818	145560	69 mm	16mm	4	2.29 kg
RBW26840MM	145550	52 mm	16mm	4	1.35 kg
RBW26850	145555	64 mm	16mm	4	1.6 kg


YTTERLIGARE PRODUKTINFORMATION

nVent LENTON Speed Sleeve is a compression-only splicing system. It should never be used for tension applications.

Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the installation instructions.

DIAGRAMS

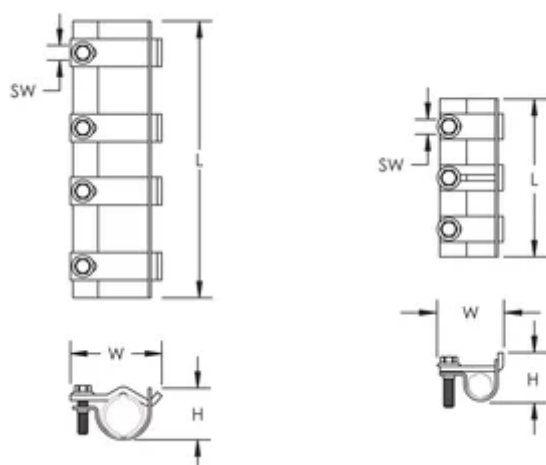

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE