

T-Series Vertical Transition Sleeve



DESIGN

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice different diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

SPECIFIKATIONER

Slutför:	Vanligt
Hylsa:	Standardlängd
Material:	Stål
100% amerikanskt innehåll:	Ja

Table 1/2

Katalognummer	Armeringsstorlek, metrisk	Armeringsstorlek, USA	Armeringsstorlek, Kanada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Längd 1 (L1)
RBT1114101A	43 mm, 36 mm	#14, #11	45M., 35M	70 mm	52 mm	152 mm
RBT1418101A	57 mm, 43 mm	#18, #14	55M, 45M	86 mm	67 mm	165 mm

Table 2/2

Katalognummer	Längd 2 (L2)	Enhetens vikt
---------------	--------------	---------------


RBT1114101A	76 mm	2.19 kg
RBT1418101A	76 mm	3.55 kg

YTTERLIGARE PRODUKTINFORMATION

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

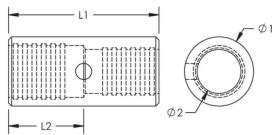

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE