

Air Terminal Base, Stamped Adjustable, Imperial Thread

Power Utilities



DESIGN

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping


SPECIFIKATIONER

Table 1/1			
Katalognummer	Ledarstorlek, UL	Höjd (H)	Bredd (W)
LPA30212	Klass 1 - klass 2 (4/0 max.)	34.92 mm	101.600 mm

YTTERLIGARE PRODUKTINFORMATION

Vertical type bases are factory pre-configured for vertical mount applications.

DIAGRAMS

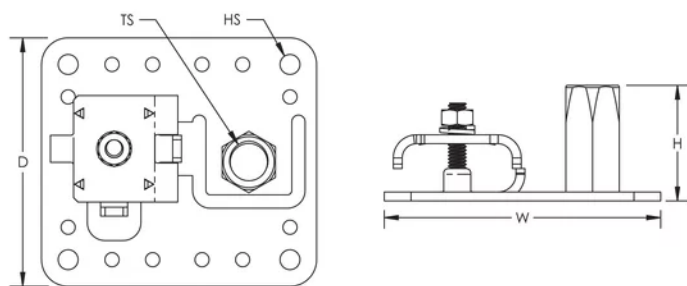

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE