


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

KATALOGNUMMER

20848-617

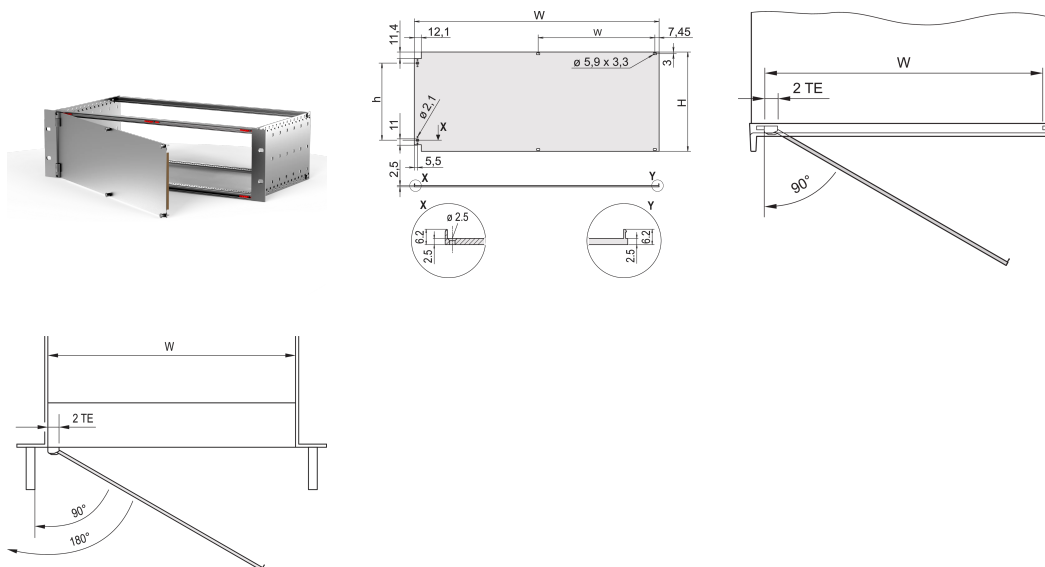

Front panel with textile EMC gasket, side hinged assembly.

CERTIFIERINGAR



DESIGN

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUKTATTRIBUT

Produkttyp: Frontpanel

Typ: Frontpanel utan handtag

Montering: Gångjärn, sida

EMC-skärmning: Nej (kan eftermonteras)

Packningstyp: Textile

Material: Aluminium

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Rackhöjd: 6 U

Höjd: 261.8 mm

Rackbredd: 84 HP

Bredd: 426.4 mm

Förpackningskvantitet: 1

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE