


Front Panel EMC Textile Shielding Kit, -40...+85°C, 3 U, 10 Pieces

Power Utilities

KATALOGNUMMER

21102-853

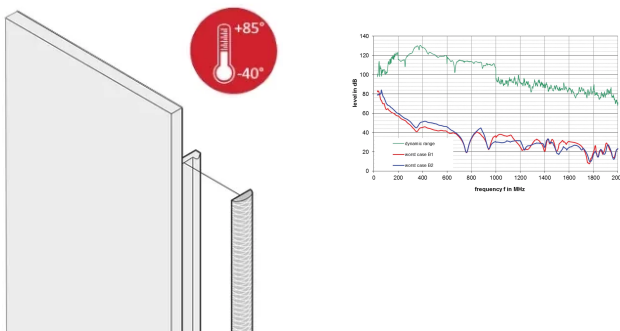

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel. For an expanded temperature range up to +85°C.

CERTIFIERINGAR



DESIGN

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +85 °C

PRODUKTATTRIBUT

Produkttyp: Skyddssats

Produktfamilj: EuropacPRO; PropacPRO; RatiopacPRO AIR; PropacPRO; Insticksenhet av ramtyp

Rackhöjd: 3 U

Förpackningskvantitet: 10

YTTERLIGARE PRODUKTINFORMATION

EMC gaskets (textile) are required for shielding the front panels.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE