
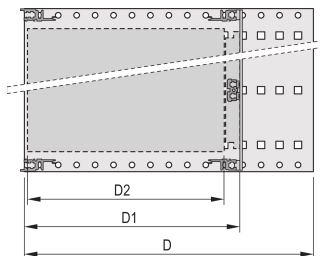
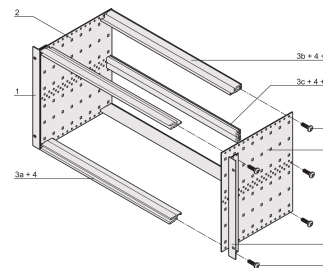


EuropacPRO 19" Subrack Kit for Backplane, Slide Rail, 3 U, 355 mm

Power Utilities

KATALOGNUMMER

24553-134

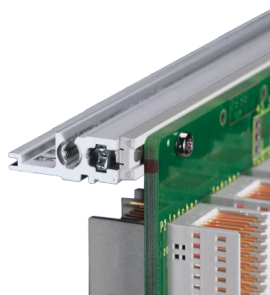

Non-shielded subrack for backplane, subrack can be assembled on slide rails to support the subrack inside a cabinet.

CERTIFIERINGAR



DESIGN

Subrack with side panel type F ("Flexible"), 19" bracket is depth-adjustable

Subrack can be used with slide rails

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 11 kg

Threaded insert, insulation strip pre-fitted

PRODUKTATTRIBUT

Produkttyp: Subrack/chassi

Rackhöjd: 3 U

Rackbredd: 84 HP

Djup: 355 mm

För montering: Bakplan

Kortdjup: 160 mm; 220 mm; 280 mm; 340 mm

EMC-skärmning: Nej

Packningstyp: Rostfritt stål

Statisk belastning: 11 kgf

Handtag medföljer: Nej

Montering: Rack

Överensstämmer med.: IEC 60297-3-103

Förpackningskvantitet: 1

YTTERLIGARE PRODUKTINFORMATION

Alternative product for older EuropacLab and Europac subrack series.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE