


EuropacPRO Cover Plate for Bolting to Rugged Side Panel, 84 HP, 235 mm

Energiföretag

KATALOGNUMMER

24568-008

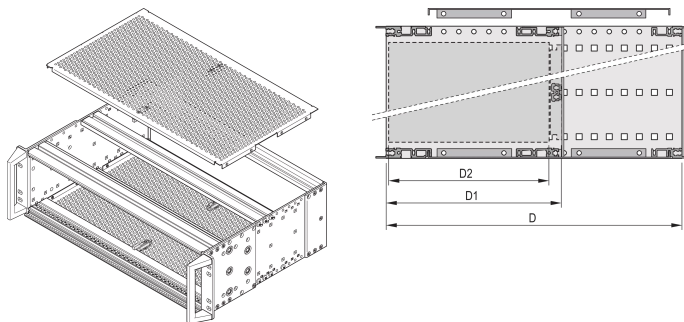

A cover plate is used for electromagnetic shielding or as mechanical protection.

CERTIFIERING



FUNKTIONER

Perforation degree 58%

PRODUKTATTRIBUT

Product Type: Skyddsplåt

Product Family: EuropacPRO

Type: Perforerad

Rack Width: 84 HP

Depth: 235 mm

Package Quantity: 1

Package Unit: Par

Torque: 2,1 N·m

ADDITIONAL PRODUCT DETAILS

A top cover locking mechanism is optionally available that also fixes the top cover in the front and rear guide rail.

4 stainless steel EMC contact strips per subrack are required for shielding, please order separately.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE